


Stamped U-Bolt Pipe Clamp, 90°



CERTIFICATIONS

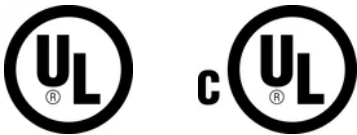

FEATURES

Clamp for bonding of pipes, handrails and exhaust stacks to the lightning protection system

Listed to UL® 96

SPECIFICATIONS

 

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Table 1/1

Catalog Number	Material	Outer Diameter (OD)	Depth (D)	Height (H)	Width (W)	Unit Weight
LPA5962	Aluminum, Stainless Steel 304 (EN 1.4301)	48.3 - 66.67 mm	50.8mm	92 mm	118.75 mm	0.21 kg
LPC5962	Copper, Stainless Steel 304 (EN 1.4301)	48.3 - 66.67 mm	50.8mm	92 mm	118.75 mm	0.23 kg

CatalogNumber	Material	Outer Diameter (OD)	Depth (D)	Height (H)	Width (W)	Unit Weight
LPA5963	Aluminum, Stainless Steel 304 (EN 1.4301)	66.8 - 92.2 mm	50.8mm	119.19 mm	139.7 mm	0.29 kg
LPC5963	Copper, Stainless Steel 304 (EN 1.4301)	66.8 - 92.2 mm	50.8mm	119.19 mm	139.7 mm	0.35 kg

DIAGRAMS

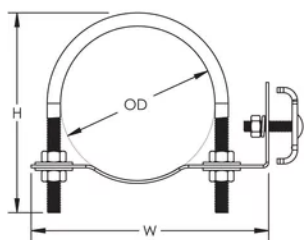

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE