


Grid Straps

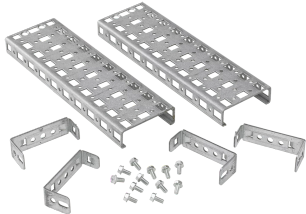

The Grid Straps are provided with specially designed rectangular holes to allow the use of cage nuts or front-loading cage nuts. Mounting holes are provided on 25-mm centers. Grid Straps are available with either 1 row or 3 rows of holes and are furnished in pairs. Mounting hardware to attach Grid Straps to the frame or to other Grid Straps is included.

FEATURES

Can be mounted vertically between horizontally mounted Grid Straps

Can be mounted left-to-right horizontally between front-to-back pairs or from the sides of the ProLine frame

Can be mounted front-to-back horizontally across the bottom or sides of the ProLine frame

When mounting width-wise from vertical to vertical, the grid strap chosen must be 100mm greater than the nominal size (i.e. 800mm wide enclosure would take a 900mm grid strap in this orientation)

Furnished in pairs, and constructed from 14 gauge (1.75mm) conductive steel

SPECIFICATIONS

Thickness: 1.9mm
Finish: Galvanized

Table 1/1					
Catalog Number	Article Number	Material	Fits Frame Depth	Hole Pattern	Quick Ship
PGH1S4	90430	Mild Steel	400mm	One Row	No
PGH3S12	16028	Mild Steel	1200mm	Three Rows	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE