

# Prefabricated Gate Jumper Assembly

## Power Utilities



### FEATURES

Ideal for when nVent ERICO Cadweld connections cannot be made to aluminum pipe or thin-wall steel tube

Jumper conductor is insulated

Stainless steel hardware included

Available in either left or right-hand orientation

### SPECIFICATIONS

Table 1/1

Catalog Number	Fixed Gate Diameter, Nominal	Fixed Gate Diameter, Actual (Ø1)	Post Frame Diameter, Nominal	Post Frame Diameter, Actual (Ø2)	Jumper Conductor Size	Jumper Length
A238EB2S12LH	2 1/2"	73.20 mm	1 1/4"	42.20 mm	4/0 Stranded	305 mm


### ADDITIONAL PRODUCT DETAILS

"Fixed gate" refers to the pipe on the fence itself, while "post frame" refers to the post on the swinging door.

Left hand orientation shown in diagram.

A238-EB-2S-12-LH		
A238	Series	
EB	Clamp Code	EB = 2 1/2" Gate, 1 1/4" Post EC = 2 1/2" Gate, 1 1/2" Post FB = 3" Gate, 1 1/4" Post FC = 3" Gate, 1 1/2" Post GB = 3 1/2" Gate, 1 1/4" Post GC = 3 1/2" Gate, 1 1/2" Post HB = 4" Gate, 1 1/4" Post HC = 4" Gate, 1 1/2" Post
2S	4/0 AWG Flexible Jumper Designation	
12	Jumper Length (inches)	
LH	Jumper Side	LH = Left Hand RH = Right Hand

## DIAGRAMS

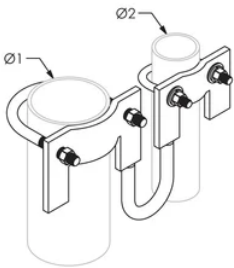

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**