

Cast Bonding Lug



CERTIFICATIONS



FEATURES

Provides contact area for main sized bonding

SPECIFICATIONS

Conductor Size, UL: Class 1 - Class 2 (4/0 Max);Secondary

Table 1/2


Catalog Number	Material	Finish	Hole Size (HS)	Contact Area	Depth (D)	Height (H)
LPA55112	Aluminum	Bare	14.29 mm	19 cm ² Min	39.69mm	25.4 mm
LPA55114	Aluminum	Bare	7.94 mm	19 cm ² Min	39.69mm	25.4 mm
LPA55138	Aluminum	Bare	11.11 mm	19 cm ² Min	39.69mm	25.4 mm
LPC55112	Brass	Bare	14.29 mm	19 cm ² Min	39.69mm	25.4 mm

CatalogNumber	Material	Finish	Hole Size (HS)	Contact Area	Depth (D)	Height (H)
LPC55114	Brass	Bare	7.94 mm	19 cm ² Min	39.69mm	25.4 mm
LPC55138	Brass	Bare	11.11 mm	19 cm ² Min	39.69mm	25.4 mm
LPC551L12	Brass	Tinned	14.29 mm	19 cm ² Min	39.69mm	25.4 mm
LPC551L38	Brass	Tinned	11.11 mm	19 cm ² Min	39.69mm	25.4 mm

Table 2/2

Catalog Number	Width (W)	Unit Weight	Certifications
LPA55112	98.42 mm	0.09 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPA55114	98.42 mm	0.09 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPA55138	98.42 mm	0.09 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC55112	98.42 mm	0.24 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC55114	98.42 mm	0.24 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC55138	98.42 mm	0.24 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC551L12	98.42 mm	0.24 kg	
LPC551L38	98.42 mm	0.24 kg	

DIAGRAMS

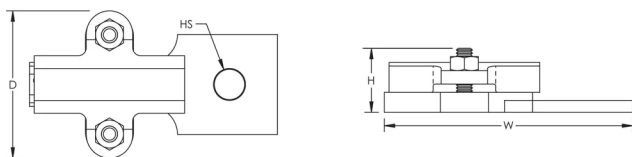

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY	ERICO	HOFFMAN	ILSCO	SCHROFF	TRACHTE
-------	-------	---------	-------	---------	---------