

Female-Male Swivel Adaptor, Imperial Thread



CERTIFICATIONS



FEATURES

Allows air terminal to be positioned vertically when base is on a sloping roof

Male thread includes locknut for positioning

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Thread Size 1 (TS1)	Thread Size 2 (TS2)	Length 1 (L1)
LPA2832F2M		Aluminum		1/2" UNC	1/2" UNC	44.45 mm
LPA2842F5M		Aluminum		1/2" UNC	5/8" UNC	44.45 mm
LPA2845F2M		Aluminum		5/8" UNC	1/2" UNC	44.45 mm
LPA2855F5M		Aluminum		5/8" UNC	5/8" UNC	44.45 mm


CatalogNumber	Article Number	Material	Finish	Thread Size 1 (TS1)	Thread Size 2 (TS2)	Length 1 (L1)
LPS2832F2M		Stainless Steel 304 (EN 1.4301)		1/2" UNC	1/2" UNC	44.45 mm
LPS2845F2M		Stainless Steel 304 (EN 1.4301)		5/8" UNC	1/2" UNC	44.45 mm
LPS2855F5M		Stainless Steel 304 (EN 1.4301)		5/8" UNC	5/8" UNC	44.45 mm
LPC2813F3M	701974	Copper		3/8" UNC	3/8" UNC	44.45 mm
LPC281L3F3M		Copper	Tinned	3/8" UNC	3/8" UNC	44.45 mm
LPC2822F3M		Copper		1/2" UNC	3/8" UNC	44.45 mm
LPC2823F2M		Copper		3/8" UNC	1/2" UNC	44.45 mm
LPC2832F2M		Copper		1/2" UNC	1/2" UNC	44.45 mm
LPC2842F5M		Copper		1/2" UNC	5/8" UNC	44.45 mm
LPC2845F2M		Copper		5/8" UNC	1/2" UNC	44.45 mm
LPC2855F5M		Copper		5/8" UNC	5/8" UNC	44.45 mm

Table 2/2

Catalog Number	Article Number	Length 2 (L2)	Unit Weight	Certifications
LPA2832F2M		69.85 mm	0.07 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPA2842F5M		69.85 mm	0.07 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPA2845F2M		69.85 mm	0.07 kg	E202878-Combined_CoC, E202878-Combined_CoC

Catalog Number	Article Number	Length 2 (L2)	Unit Weight	Certifications
LPA2855F5M		69.85 mm	0.07 kg	
LPS2832F2M		69.85 mm	0.22 kg	
LPS2845F2M		69.85 mm	0.22 kg	
LPS2855F5M		69.85 mm	0.22 kg	
LPC2813F3M	701974	69.85 mm	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC281L3F3M		69.85 mm	0.23 kg	
LPC2822F3M		69.85 mm	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2823F2M		69.85 mm	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2832F2M		69.85 mm	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2842F5M		69.85 mm	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2845F2M		69.85 mm	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2855F5M		69.85 mm	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC

DIAGRAMS

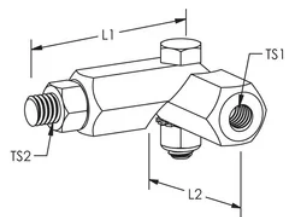

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE