

# SA Transition Coupler



## FEATURES

Designed to splice different diameter bars where the second bar can be rotated and is not restricted in its axial direction

Durable mounting plates allow for easy attachment to forms

Built-in thread cover or screw-in plug protects internal threads from concrete paste contamination

## SPECIFICATIONS

Table 1/3

| Catalog Number | Material | Finish | 100% U.S. Domestic Content | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada |
|----------------|----------|--------|----------------------------|--------------------|----------------|--------------------|
| EL2016SA       | Steel    | Plain  | Yes                        | 20 mm, 16 mm       | #6, #5         | 20M, 15M           |

Table 2/3

| Catalog Number | Hex Width (W) | Height (H) | Length (L) | Bar Depth 1 (BD1) | Bar Depth 2 (BD2) | Bar Gap (BG) |
|----------------|---------------|------------|------------|-------------------|-------------------|--------------|
| EL2016SA       | 27 mm         | 57 mm      | 79mm       | 28mm              | 29mm              | 22mm         |


Table 3/3

| Catalog Number | Unit Weight |
|----------------|-------------|
| EL2016SA       | 0.27 kg     |

**Designed to Meet:**

AASHTO;ABNT NBR 8548:1984;ACI 318 Type 1 (125% Specified Yield);ACI 318 Type 2 (Specified Tensile);ACI 349;ACI 359;AS3600

DIAGRAMS

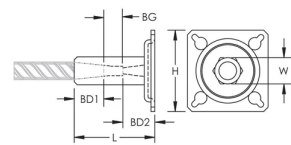

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

|                          |                 |                  |                      |
|--------------------------|-----------------|------------------|----------------------|
| <b>North America</b>     | <b>Europe</b>   | <b>Europe</b>    | <b>APAC</b>          |
| +1.800.753.9221          | Netherlands:    | Germany:         | Shanghai:            |
| Option 1 – Customer Care | +31 800-0200135 | 800 1890272      | + 86 21 2412 1618/19 |
| Option 2 – Technical     | France:         | Other Countries: | Sydney:              |
| Support                  | +33 800 901 793 | +31 13 5835404   | +61 2 9751 8500      |



Our powerful portfolio of brands:

CADDYERICOHOFFMANILSCOSCHROFFTRACHTE