

Front Panel, Anodized With Untreated Edges, Unshielded

Front Panel, anodized with untreated edges, unshielded. The panels enable mounting on horizontal rails.



CERTIFICATIONS



FEATURES

Partial width front panel, Al, 2.5 mm

Al, clear anodized, untreated edges

SPECIFICATIONS

Depth (D):	2.5mm
Material:	Aluminum
Finish:	Anodized
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel without Handle

Table 1/3

Catalog Number	Rack Height	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish
30810-433	3U	2HP	1	None	Screw-on Front	Anodized

CatalogNumber	Rack Height	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish
30818-271	2U	84HP	1	None	Screw-on Front	Anodized
30818-272	3U	3HP	1	None	Screw-on Front	Anodized
30818-273	3U	4HP	1	None	Screw-on Front	Anodized
30818-274	3U	5HP	1	None	Screw-on Front	Anodized
30818-275	3U	6HP	1	None	Screw-on Front	Anodized
30818-276	3U	7HP	1	None	Screw-on Front	Anodized
30818-277	3U	8HP	1	None	Screw-on Front	Anodized
30818-279	3U	10HP	1	None	Screw-on Front	Anodized
30818-281	3U	12HP	1	None	Screw-on Front	Anodized
30818-282	3U	14HP	1	None	Screw-on Front	Anodized
30818-289	3U	21HP	1	None	Screw-on Front	Anodized
30818-296	3U	28HP	1	None	Screw-on Front	Anodized
30818-310	3U	42HP	1	None	Screw-on Front	Anodized
30818-331	3U	63HP	1	None	Screw-on Front	Anodized
30818-352	3U	84HP	1	None	Screw-on Front	Anodized
30818-434	4U	84HP	1	None	Screw-on Front	Anodized
30818-518	6U	4HP	1	None	Screw-on Front	Anodized
30818-519	6U	5HP	1	None	Screw-on Front	Anodized

CatalogNumber	Rack Height	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish
30818-520	6U	6HP	1	None	Screw-on Front	Anodized
30818-521	6U	7HP	1	None	Screw-on Front	Anodized
30818-522	6U	8HP	1	None	Screw-on Front	Anodized
30818-524	6U	10HP	1	None	Screw-on Front	Anodized
30818-526	6U	12HP	1	None	Screw-on Front	Anodized
30818-528	6U	14HP	1	None	Screw-on Front	Anodized
30818-530	6U	16HP	1	None	Screw-on Front	Anodized
30818-535	6U	21HP	1	None	Screw-on Front	Anodized
30818-542	6U	28HP	1	None	Screw-on Front	Anodized
30818-556	6U	42HP	1	None	Screw-on Front	Anodized
30818-577	6U	63HP	1	None	Screw-on Front	Anodized
30818-598	6U	84HP	1	None	Screw-on Front	Anodized
30818-747	6U	2HP	1	None	Screw-on Front	Anodized

Table 2/3						
Catalog Number	Rear Finish	Treated Edges	Complies With	EMC Shielding	Height (H)	Width (W)
30810-433	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	9.8mm
30818-271	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	84mm	426.4mm
30818-272	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	14.9mm

CatalogNumber	Rear Finish	Treated Edges	Complies With	EMC Shielding	Height (H)	Width (W)
30818-273	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	20mm
30818-274	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	25mm
30818-275	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	30.1mm
30818-276	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	35.2mm
30818-277	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	40.3mm
30818-279	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	50.5mm
30818-281	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	60.6mm
30818-282	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	70.8mm
30818-289	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	106.3mm
30818-296	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	141.9mm
30818-310	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	213mm
30818-331	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	319.7mm
30818-352	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	426.4mm
30818-434	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	172.9mm	426.4mm
30818-518	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	20mm

CatalogNumber	Rear Finish	Treated Edges	Complies With	EMC Shielding	Height (H)	Width (W)
30818-519	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	25mm
30818-520	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	30.1mm
30818-521	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	35.2mm
30818-522	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	40.3mm
30818-524	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	50.5mm
30818-526	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	60.6mm
30818-528	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	70.8mm
30818-530	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	80.9mm
30818-535	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	106.3mm
30818-542	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	141.9mm
30818-556	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	213mm
30818-577	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	319.7mm
30818-598	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	426.4mm
30818-747	Anodized	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	9.8mm

Table 3/3

Catalog Number	Quick Ship
----------------	------------


30810-433	No
30818-271	No
30818-272	No
30818-273	No
30818-274	No
30818-275	No
30818-276	No
30818-277	No
30818-279	No
30818-281	No
30818-282	No
30818-289	No
30818-296	No
30818-310	No
30818-331	No
30818-352	No
30818-434	No
30818-518	No
30818-519	No

30818-520	No
30818-521	No
30818-522	No
30818-524	No
30818-526	No
30818-528	No
30818-530	No
30818-535	No
30818-542	No
30818-556	No
30818-577	No
30818-598	No
30818-747	No

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

DIAGRAMS

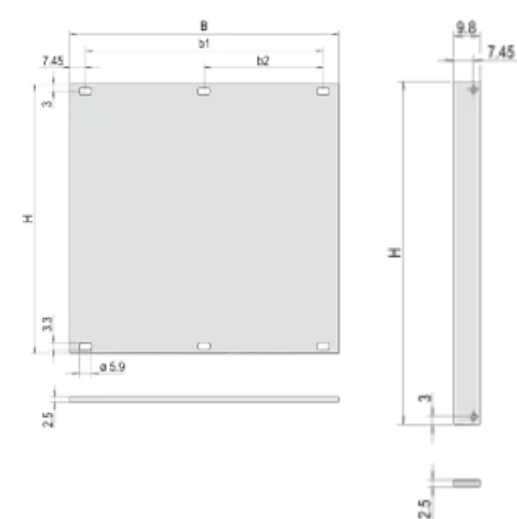

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE