

# nVent CADDY Cat CM U-Hook, Strut Mount



## CERTIFICATIONS



## FEATURES

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Integrated quick-attach T-nut allows U-Hooks to be quickly mounted to strut

System offers a convenient pathway for wires and cables

Specially designed U-Hooks have large-diameter, rounded support surfaces

Rounded edges help prevent over-bending and kinking of cables

Ideal for retrofit applications where cable runs need to be routed around existing building infrastructure

Compliant with NEC® and ANSI®/TIA structured cabling systems standards

## SPECIFICATIONS

|                             |                    |
|-----------------------------|--------------------|
| <b>Finish:</b>              | Electrogalvanized  |
| <b>Included Components:</b> | Quick-Attach T-Nut |
| <b>Material:</b>            | Steel              |


Table 1/2

| Catalog Number | Article Number | Cable Capacity, Cat 5e | Cable Capacity, Cat 6 | Cable Capacity, Cat 6A | A | Area |
|----------------|----------------|------------------------|-----------------------|------------------------|---|------|
|----------------|----------------|------------------------|-----------------------|------------------------|---|------|

|          |        |     |     |     |        |                    |
|----------|--------|-----|-----|-----|--------|--------------------|
| CAT300CM | 181984 | 700 | 525 | 325 | 304 mm | 812mm <sup>2</sup> |
| CAT200CM | 181982 | 450 | 350 | 215 | 203 mm | 533mm <sup>2</sup> |

| Table 2/2      |                |                |             |
|----------------|----------------|----------------|-------------|
| Catalog Number | Article Number | Hole Size (HS) | Static Load |
| CAT300CM       | 181984         | 9.5 mm         | 440N        |
| CAT200CM       | 181982         | 9.5 mm         | 440N        |

### DIAGRAMS

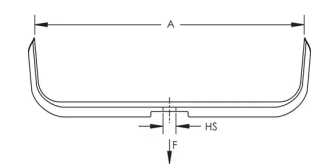

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

