

Rebar Bonding Plate Cable Bond



CERTIFICATIONS



FEATURES

Connects Rebar Bonding Plate to lightning conductor

SPECIFICATIONS

Material: Brass
Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Table 1/2


Catalog Number	Thread Size (TS)	Screw Length (L)	Depth (D)	Height (H)	Width (W)	Unit Weight
LPC468	1/2" UNC	23.62mm	60.33mm	50 mm	76.2 mm	0.39 kg
LPLC468	1/2" UNC	23.62mm	60.33mm	50 mm	76.2 mm	1 kg

Table 2/2

Catalog Number	Certifications
----------------	----------------

LPC468	E202878-Combined_CoC, E202878-Combined_CoC
LPLC468	

DIAGRAMS

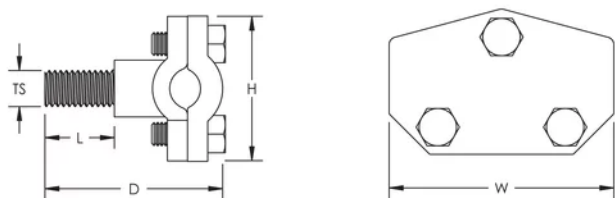

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE