


Cross Fitting Galvanized

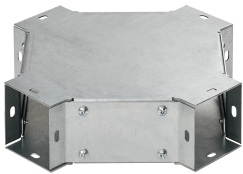

Lay-in Galvanized 90-Degree Crosses are used when there are four branches. It can be used as a 90-degree elbow or a 90-degree flush tee by adding Closure Plates. Top, bottom and side covers removable.

FEATURES

Lay-in Galvanized 90-Degree Crosses are used when there are four branches

It can be used as a 90-degree elbow or a 90-degree flush tee by adding Closure Plates

Top, bottom and side covers removable

SPECIFICATIONS

Finish: Galvanized

Material: Mild Steel

Table 1/1

Catalog Number	Article Number	Type	Height	Width	Thickness	Quick Ship
F44XGV	13188	Cross Fitting	102mm	102mm	1.52mm	No
F88XGV	13192	Cross Fitting	203mm	203mm	1.9mm	No
F22XGV	13187	Cross Fitting	64mm	64mm	1.52mm	No
F66XGV	13191	Cross Fitting	152mm	152mm	1.52mm	No
F1010XGV	13193	Cross Fitting	254mm	254mm	1.9mm	No
F1212XGV	13194	Cross Fitting	305mm	305mm	1.9mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE