


# Backplane With Through-Connected Signal Lines

Backplane with Through Connected Signal Lines.

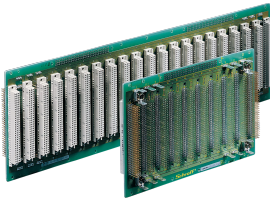

## CERTIFICATIONS



## FEATURES

Power supply at each connector position (row 1 + 32)

Adaptation fields for power connections on 2-layer backplanes

## SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23007-421	Backplane	21	3U	90 Signal Lines	4HP	C96F
23007-051	Backplane	21	3U	60 Signal Lines	4HP	C96F
23007-040	Backplane	10	3U	60 Signal Lines	4HP	C96F
23007-410	Backplane	10	3U	90 Signal Lines	4HP	C96F

CatalogNumber	Product Type	Number ofSlots	Rack Height	BackplaneType	Slot Width	ConnectorType
23007-188	Backplane	28	3U	60 Signal Lines	3HP	
23007-010	Backplane	10	3U	60 Signal Lines	4HP	C64F
23007-081	Backplane	21	3U	60 Signal Lines	4HP	
23007-114	Backplane	14	3U	60 Signal Lines	3HP	C64F
23007-158	Backplane	28	3U	60 Signal Lines	3HP	C96F
23007-128	Backplane	28	3U	60 Signal Lines	3HP	C64F
23007-021	Backplane	21	3U	60 Signal Lines	4HP	C64F

Table 2/2

Catalog Number	Power Connector Type	Package Quantity	Quick Ship
23007-421	Fastons 6.3 x 0.8 mm	1	No
23007-051	Fastons 6.3 x 0.8 mm	1	No
23007-040	Fastons 6.3 x 0.8 mm	1	No
23007-410	Fastons 6.3 x 0.8 mm	1	No
23007-188	Fastons 6.3 x 0.8 mm	1	No
23007-010	Fastons 6.3 x 0.8 mm	1	No
23007-081	Fastons 6.3 x 0.8 mm	1	No
23007-114	Fastons 6.3 x 0.8 mm	1	No
23007-158	Fastons 6.3 x 0.8 mm	1	No
23007-128	Fastons 6.3 x 0.8 mm	1	No

Catalog Number	Power Connector Type	Package Quantity	Quick Ship
23007-021	Fastons 6.3 x 0.8 mm	1	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE