


Front Panel, Unshielded, Cutout for Coax Connectors, 2.5 mm, Al, Front Anodized, Rear Conductive

CATALOG NUMBER

30118-355

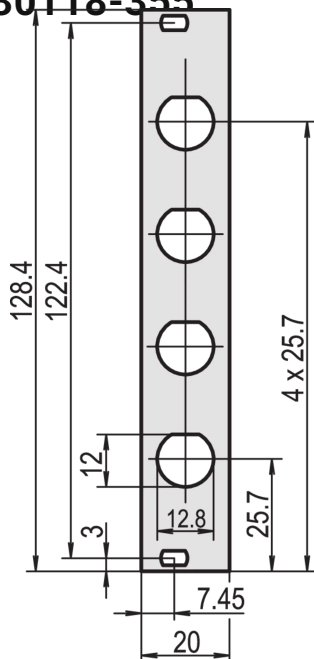

Aluminum, 2.5 mm, front anodized, conductive, unshielded version.

CERTIFICATIONS



FEATURES

Al, 2.5 mm, front anodized, conductive

3 U, 4 HP


PRODUCT ATTRIBUTES

Product Type: Front Panel
Type: Front Panel without Handle
Accessory Type: Front panel
Mounting: Screw-on Front
EMC Shielding: No
Material: Aluminum
Front Finish: Anodized
Rear Finish: Conductive
Treated Edges: No
Rack Height: 3U
Height (H): 128.4mm
Rack Width: 4HP
Width (W): 19.98mm
Depth (D): 2.5mm
Complies With: IEC 60297-3-101; IEEE 1101.1/10
Package Quantity: 1
Finish: Anodized; Passivated
Net Weight: 0.013kg

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

DIAGRAMS

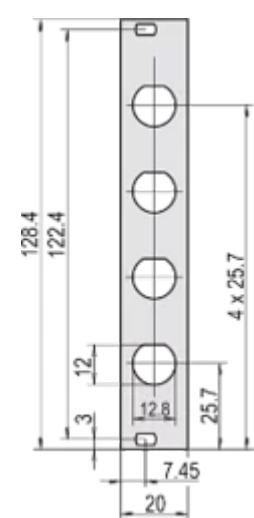

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE