


# Novastar Glazed Acrylic Glass Door

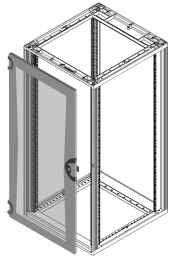

Glazed / Glass doors for aluminum frame cabinets with attractive design, ideally suited for general electronics, test & measurement, audio/video and broadcasting applications.

## CERTIFICATIONS



## FEATURES

Mounting front or rear

Opening angle 180°

Lock with key

## SPECIFICATIONS

**Product Type:** Cabinet Door

**Material:** Steel

Table 1/2

| Catalog Number | Rack Height | Height | Width | Package Quantity | Color      | Color Code |
|----------------|-------------|--------|-------|------------------|------------|------------|
| 25230-092      | 6U          | 322mm  | 553mm | 1                | Black Grey | RAL 7021   |
| 25230-093      | 9U          | 456mm  | 553mm | 1                | Black Grey | RAL 7021   |
| 25230-094      | 12U         | 589mm  | 553mm | 1                | Black Grey | RAL 7021   |

| CatalogNumber | Rack Height | Height | Width | Package Quantity | Color      | Color Code |
|---------------|-------------|--------|-------|------------------|------------|------------|
| 25230-095     | 16U         | 767mm  | 553mm | 1                | Black Grey | RAL 7021   |
| 25230-096     | 20U         | 945mm  | 553mm | 1                | Black Grey | RAL 7021   |
| 25230-097     | 25U         | 1167mm | 553mm | 1                | Black Grey | RAL 7021   |
| 25230-098     | 34U         | 1567mm | 553mm | 1                | Black Grey | RAL 7021   |
| 25230-099     | 38U         | 1745mm | 533mm | 1                | Black Grey | RAL 7021   |
| 25230-100     | 43U         | 1967mm | 533mm | 1                | Black Grey | RAL 7021   |
| 25230-101     | 47U         | 2145mm | 553mm | 1                | Black Grey | RAL 7021   |
| 25230-102     | 29U         | 1345mm | 553mm | 1                | Black Grey | RAL 7021   |
| 26230-092     | 6U          | 322mm  | 553mm | 1                | Light Grey | RAL 7035   |
| 26230-093     | 9U          | 456mm  | 553mm | 1                | Light Grey | RAL 7035   |
| 26230-094     | 12U         | 589mm  | 533mm | 1                | Light Grey | RAL 7035   |
| 26230-095     | 16U         | 767mm  | 533mm | 1                | Light Grey | RAL 7035   |
| 26230-096     | 20U         | 945mm  | 553mm | 1                | Light Grey | RAL 7035   |
| 26230-097     | 25U         | 1167mm | 553mm | 1                | Light Grey | RAL 7035   |
| 26230-098     | 34U         | 1567mm | 553mm | 1                | Light Grey | RAL 7035   |
| 26230-099     | 38U         | 1745mm | 553mm | 1                | Light Grey | RAL 7035   |
| 26230-100     | 43U         | 1967mm | 553mm | 1                | Light Grey | RAL 7035   |
| 26230-101     | 47U         | 2145mm | 553mm | 1                | Light Grey | RAL 7035   |

| CatalogNumber | Rack Height | Height | Width | Package Quantity | Color      | Color Code |
|---------------|-------------|--------|-------|------------------|------------|------------|
| 26230-102     | 29U         | 1345mm | 553mm | 1                | Light Grey | RAL 7035   |

Table 2/2

| Catalog Number | Finish        | Type       | Quick Ship |
|----------------|---------------|------------|------------|
| 25230-092      | Powder Coated | Glass Door | No         |
| 25230-093      | Powder Coated | Glass Door | No         |
| 25230-094      | Powder Coated | Glass Door | No         |
| 25230-095      | Powder Coated | Glass Door | No         |
| 25230-096      | Powder Coated | Glass Door | No         |
| 25230-097      | Powder Coated | Glass Door | No         |
| 25230-098      | Powder Coated | Glass Door | No         |
| 25230-099      | Powder Coated | Glass Door | No         |
| 25230-100      | Powder Coated | Glass Door | No         |
| 25230-101      | Powder Coated | Glass Door | No         |
| 25230-102      | Powder Coated | Glass Door | No         |
| 26230-092      | Powder Coated | Glass Door | No         |
| 26230-093      | Powder Coated | Glass Door | No         |
| 26230-094      | Powder Coated | Glass Door | No         |
| 26230-095      | Powder Coated | Glass Door | No         |
| 26230-096      | Powder Coated | Glass Door | No         |

| Catalog Number | Finish        | Type       | Quick Ship |
|----------------|---------------|------------|------------|
| 26230-097      | Powder Coated | Glass Door | No         |
| 26230-098      | Powder Coated | Glass Door | No         |
| 26230-099      | Powder Coated | Glass Door | No         |
| 26230-100      | Powder Coated | Glass Door | No         |
| 26230-101      | Powder Coated | Glass Door | No         |
| 26230-102      | Powder Coated | Glass Door | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**