


# TR Four Pole Distribution Block, 400 A

## Data Solutions

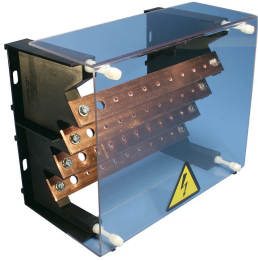

### CERTIFICATIONS



### FEATURES

Easily fixes onto DIN rail or mounts with screws

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

### SPECIFICATIONS


Catalog Number	TR-400A
Article Number	562010
Material	Copper Glass Fibre Reinforced Polyamide Plexiglass

Catalog Number	TR-400A
Max Working Voltage, IEC (Ui)	1000
Peak Short Circuit Current (Ipk)	34kA
Short Term Withstand Current (Icw) 1s	28kA
Line Side Number of Connections	1
Load Side Number of Connections	8
Hole Size (HS)	10mm
Thread Size (TS)	M6
Depth (D)	140mm
Height (H)	240mm
Width (W)	300mm
Unit Weight	2.83kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

## ADDITIONAL PRODUCT DETAILS

Line side and load side number of connections are per pole.

## DIAGRAMS

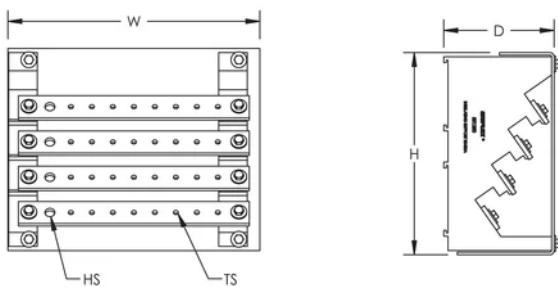

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**