


Insertor/Extractor Handle Type IET, Black Lever, Grey Button, Top; 10 pieces

 
CATALOG NUMBER

20817-654

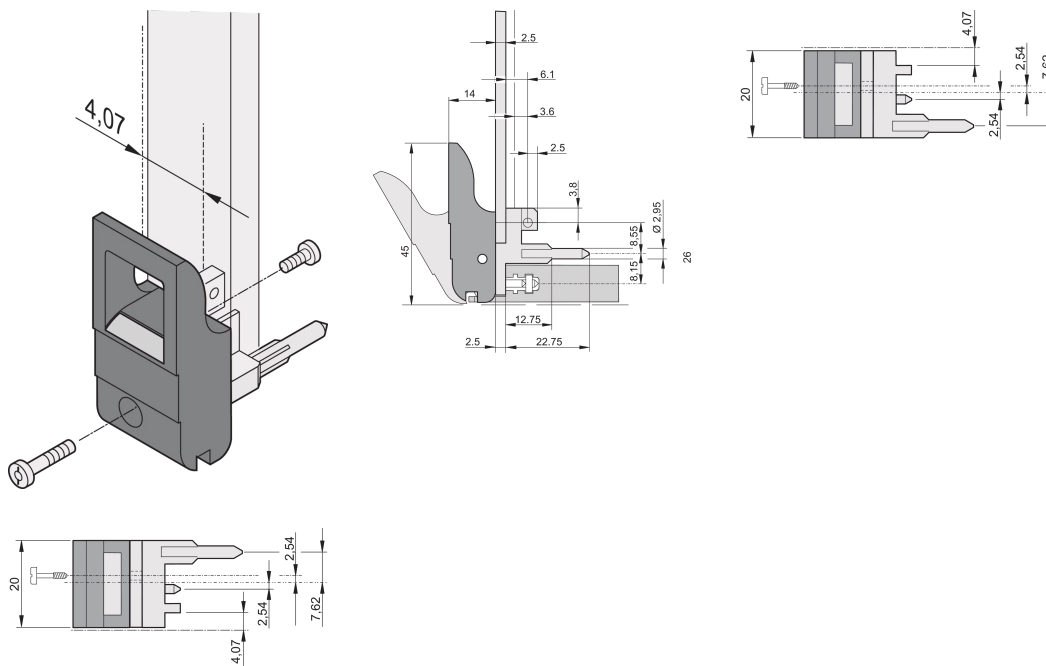

The inserter/extractor handle, type IET in accordance with IEEE 1101.10. Two of these handles can overcome a single lever force of 700 N (per pair).

CERTIFICATIONS



FEATURES


Suitable for insertion and extraction forces up to 700 N (per pair)

In accordance with IEEE 1101.10 and IEC 60297-3-102

A microswitch can be mounted

Package Quantity: 10
Handle Type: IET; Top Front; Bottom Rear I/O
Flammability Rating: UL® 94V-0
Color: Jet Black
Color Code: RAL 9005
Complies With: EN 45545-2
Depth (D): 39.15mm
Height (H): 44.65mm
Material: Polycarbonate; Zinc Alloy
Product Type: Handle
Type: Inserter/Extractor, Standard
Width (W): 19.8mm
Works With: Front Panels
Gross Weight: 0.231kg

Please order Coding pegs and Microswitch separately.

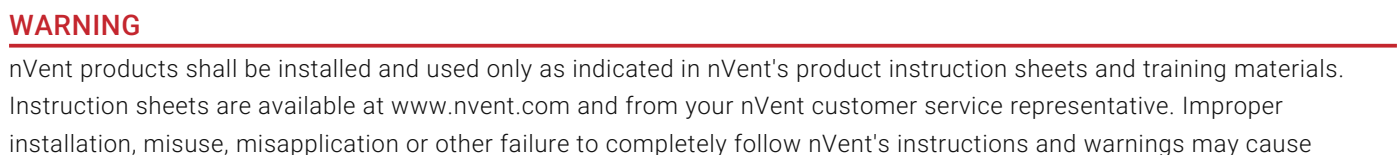

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE