


## Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

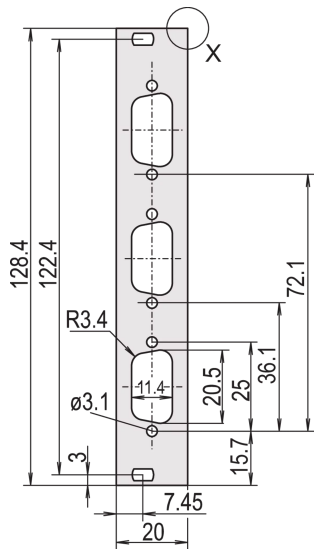

Flat front panel with cutout for D-Sub connectors.  
Shieldable for stainless steel EMC gasket.

## CERTIFICATIONS



## FEATURES

For stainless steel EMC gasket

Al, 2.5 mm, front anodized, conductive

## SPECIFICATIONS

|                        |                      |
|------------------------|----------------------|
| <b>Rack Height:</b>    | 3U                   |
| <b>Rack Width:</b>     | 4HP                  |
| <b>Material:</b>       | Aluminum             |
| <b>Finish:</b>         | Anodized; Passivated |
| <b>Accessory Type:</b> | Front panel          |
| <b>Product Type:</b>   | Front Panel          |

**Type:** Front Panel without Handle

**EMC Shielding:** No (Retrofittable)

Table 1/2

| Catalog Number | Package Quantity | Mounting       | Gasket Type         | Front Finish | Rear Finish | Number of Pins |
|----------------|------------------|----------------|---------------------|--------------|-------------|----------------|
| 30118-353      | 1                | Screw-on Front | Stainless Steel EMC | Anodized     | Conductive  | (2) 25         |
| 30118-352      | 1                | Screw-on Front | Stainless Steel EMC | Anodized     | Conductive  | (2) 15         |
| 30118-350      | 1                | Screw-on Front | Stainless Steel EMC | Anodized     | Conductive  | (1) 25         |
| 30118-351      | 1                | Screw-on Front | Stainless Steel EMC | Anodized     | Conductive  | (2) 9          |
| 30118-354      | 1                | Screw-on Front | Stainless Steel EMC | Anodized     | Conductive  | (3) 9          |
| 30118-348      | 1                | Screw-on Front | Stainless Steel EMC | Anodized     | Conductive  | (1) 9          |
| 30118-349      | 1                | Screw-on Front | Stainless Steel EMC | Anodized     | Conductive  | (1) 15         |

Table 2/2

| Catalog Number | Treated Edges | Complies With                   | Depth (D) | Height (H) | Width (W) | Quick Ship |
|----------------|---------------|---------------------------------|-----------|------------|-----------|------------|
| 30118-353      | No            | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm     | 128.4mm    | 19.98mm   | No         |
| 30118-352      | No            | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm     | 128.4mm    | 19.98mm   | No         |
| 30118-350      | No            | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm     | 128.4mm    | 19.98mm   | No         |
| 30118-351      | No            | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm     | 128.4mm    | 19.98mm   | No         |
| 30118-354      | No            | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm     | 128.4mm    | 19.98mm   | No         |
| 30118-348      | No            | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm     | 128.4mm    | 19.98mm   | No         |

| CatalogNumber | Treated Edges | Complies With                   | Depth (D) | Height (H) | Width (W) | Quick Ship |
|---------------|---------------|---------------------------------|-----------|------------|-----------|------------|
| 30118-349     | No            | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm     | 128.4mm    | 19.98mm   | No         |

## ADDITIONAL PRODUCT DETAILS


Please order fixing material (sleeves, collar screws) separately.





Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## DIAGRAMS

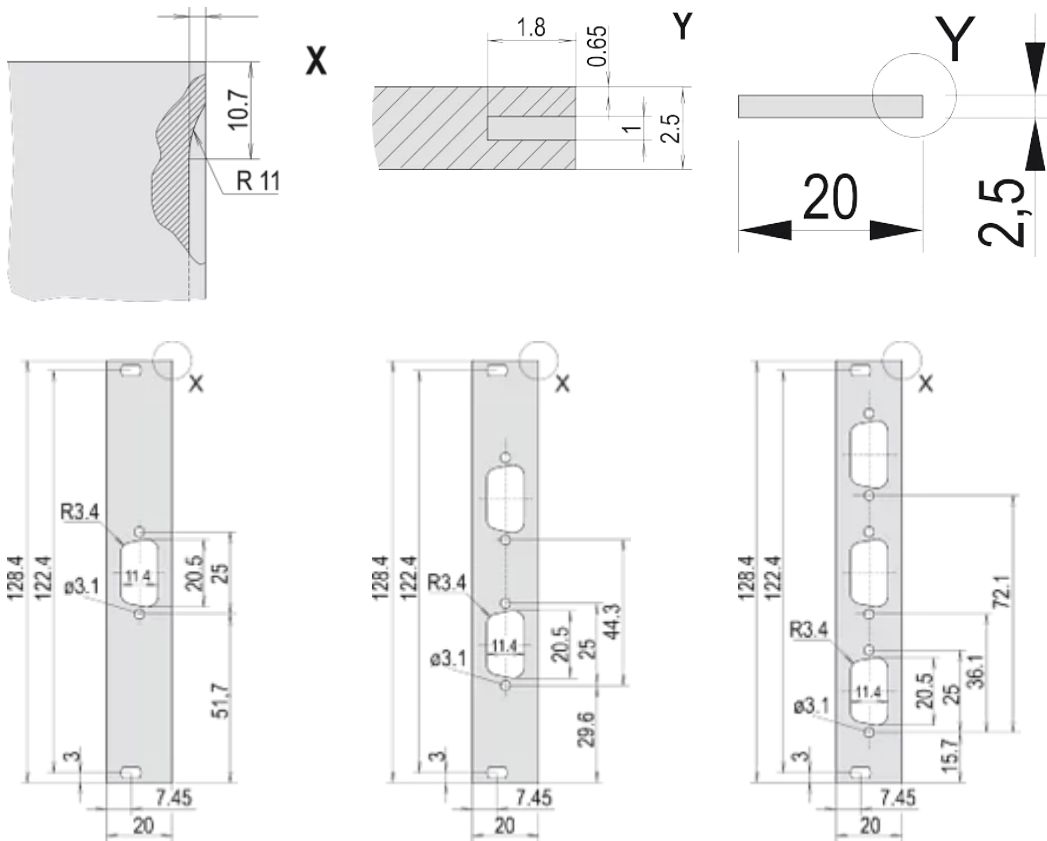

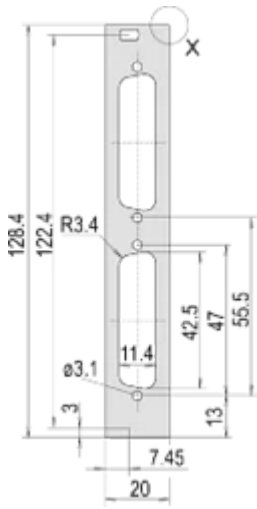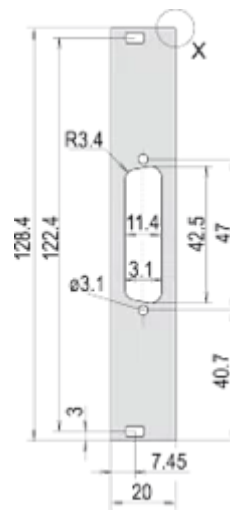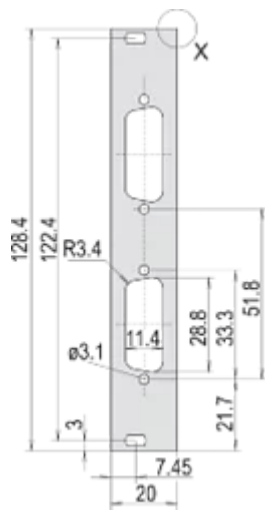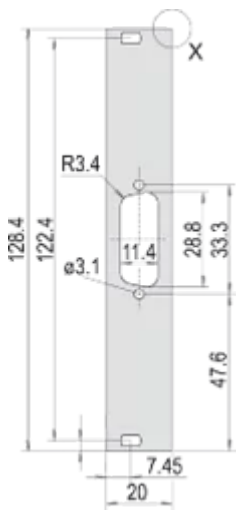

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void any warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**