


# Plastic Foot

Tip-up feet, Plastic.

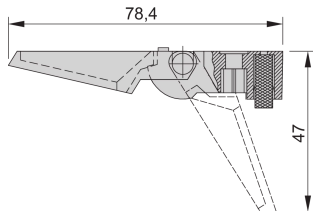

## CERTIFICATIONS



## FEATURES

Can be used instead of standard round feet

Load-carrying capacity: 25 kg per foot, max case weight 40 kg

Mounting holes are provided in bottom covers of the cases

Positioning of case is secured by anti-slip rubber inserts

## SPECIFICATIONS

|                        |                                                           |
|------------------------|-----------------------------------------------------------|
| <b>Works With:</b>     | Cases                                                     |
| <b>Product Family:</b> | RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac |
| <b>Type:</b>           | Foot; With Tip-up                                         |
| <b>Product Type:</b>   | Foot                                                      |
| <b>Material:</b>       | Polyamide                                                 |

Table 1/1

| Catalog Number | Package Quantity | Quick Ship |
|----------------|------------------|------------|
| 10603-023      | 1                | No         |
| 10603-026      | 1                | No         |

| Catalog Number | Package Quantity | Quick Ship |
|----------------|------------------|------------|
| 10603-025      | 1                | No         |
| 10603-024      | 1                | No         |

## ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**