


# Plug-In Unit Kit for PMC, Chromated, Shielded (Textile) With Handle

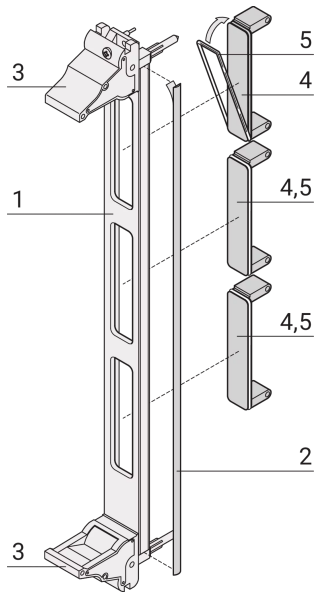

U-shaped front panel with cutout for PMC. Shieldable for textile EMC gasket.

## FEATURES

In accordance with IEEE P1386, PCI Mezzanine Card

For single 69.0 x 76.5 mm or double 139.0 x 76.5 mm modules

For standard defined I/O mezzanine modules which connect to carrier cards

PMC = PCI Mezzanine Card

FPGA = Field Programmable Gate Array

U-profile front panel 3 U, 4 HP, with textile gasketing

EMC shielding for front panel and coverings for front panel cutouts

## SPECIFICATIONS

<b>Rack Width:</b>	4HP
<b>Material:</b>	Aluminum
<b>Product Type:</b>	Front Panel
<b>Type:</b>	Front Panel with Handle (PIU)
<b>EMC Shielding:</b>	Yes

Table 1/2

Catalog Number	Rack Height	Package Quantity	Handle Type	Mounting	EMC Gasket Type	Front Finish
20836-460	3U	1	IEL	Screw-on Front	Textile	Anodized
20836-461	6U	1	IEL	Screw-on Front	Textile	Anodized

Table 2/2

Catalog Number	Rear Finish	Complies With	Finish	Quick Ship
20836-460	Conductive	PMC Mezzanine, IEEE P1386	Anodized, Passivated	No
20836-461	Conductive	PMC Mezzanine, IEEE P1386	Anodized, Passivated	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**