

107 Wraparound Strap for CPVC Pipe



CERTIFICATIONS



FEATURES

Includes flared edges to protect piping

Rated for use with CPVC fire sprinkler pipe

Includes mounting screw

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel


Table 1/2

Catalog Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A	B	C
1070125EG	32	42.2 mm	5.8 mm	41.3 mm	77.8 mm	30.2 mm
1070100EG	25	33.7 mm	5.8 mm	36.5 mm	68.3 mm	30.2 mm
1070200EG	50	60.3 mm	5.8 mm	47.6 mm	93.7 mm	30.2 mm

CatalogNumber	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A	B	C
1070150EG	40	48.3 mm	5.8 mm	44.5 mm	84.1 mm	30.2 mm
1070075EG	20	26.9 mm	5.8 mm	31.8 mm	60.3 mm	30.2 mm

Table 2/2	
Catalog Number	Hanger Spacing
1070125EG	1.95 m Max
1070100EG	1.8 m Max
1070200EG	2.4 m Max
1070150EG	2.1 m Max
1070075EG	1.65 m Max

DIAGRAMS

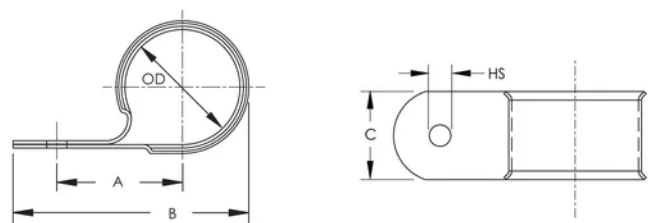

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

