

# 109 Side Mount Strap for CPVC Pipe



## CERTIFICATIONS



## FEATURES

Includes flared edges to protect piping

Rated for use with CPVC fire sprinkler pipe

Includes mounting screws

## SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel


Table 1/2

Catalog Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A	B	C
1090125EG	32	42.2 mm	5.8 mm	74.6 mm	58.7 mm	30.2 mm
1090100EG	25	33.7 mm	5.8 mm	66.7 mm	49.2 mm	30.2 mm
1090150EG	40	48.3 mm	5.8 mm	81 mm	63.5 mm	30.2 mm

CatalogNumber	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A	B	C
1090200EG	50	60.3 mm	5.8 mm	92.1 mm	76.2 mm	30.2 mm
1090075EG	20	26.9 mm	5.8 mm	58.7 mm	42.9 mm	30.2 mm

Table 2/2	
Catalog Number	Hanger Spacing
1090125EG	1.95 m Max
1090100EG	1.8 m Max
1090150EG	2.1 m Max
1090200EG	2.4 m Max
1090075EG	1.65 m Max

### DIAGRAMS

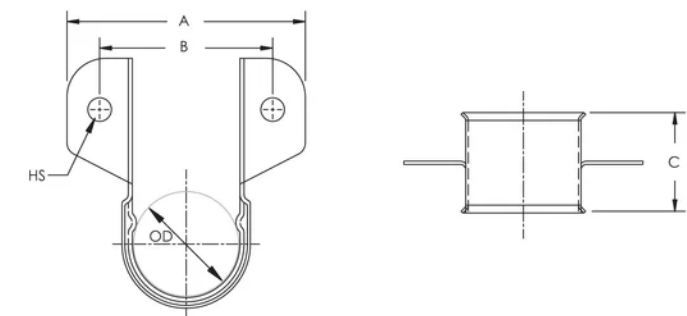

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

