

115 Standard Duty Loop Hanger



The 115 Standard Duty Loop Hanger is ideal for suspending stationary, non-insulated pipe lines, including CPVC pipes, in fire sprinkler systems. A knurled insert nut helps simplify vertical adjustments and flared edges on the base (1/2" to 4" sizes) help protect pipes from coming into contact with any sharp edges of the hanger.

CERTIFICATIONS



FEATURES

Flared edges help prevent any sharp surfaces from coming into contact with the pipe (1/2" to 4" sizes)

Retained insert nut helps ensure the loop hanger and insert nut stay together

Recommended for the suspension of stationary non-insulated pipe lines

Manufactured to use the minimum rod size permitted by NFPA® for fire sprinkler piping

Conforms with Federal Specification WW-H-171 (Type 10), Manufacturers Standardization Society (MSS) SP-58 (Type 10)

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2

Catalog Number	NB/DN	Outer Diameter (OD)	A	B	C	Static Load
1150050EG		21.3 mm	71.44 mm	28.57 mm	25.4 mm	1334N
1150075EG		26.7 mm	76.2 mm	30.16 mm	23.81 mm	1334N


CatalogNumber	NB/DN	Outer Diameter (OD)	A	B	C	Static Load
1150100EG		33.4 mm	82.55 mm	34.92 mm	23.81 mm	1334N
1150125EG		42.2 mm	90.49 mm	38.1 mm	23.81 mm	1334N
1150150EG		48.3 mm	96.84 mm	41.27 mm	23.81 mm	1334N
1150200EG		60.3 mm	107.95 mm	47.62 mm	23.81 mm	1334N
1150250EG	65	76 mm	150.8 mm	87.3 mm	50.8 mm	2340N
1150300EG	80	89 mm	166.3 mm	88.2 mm	49.7 mm	2340N
1150350EG		101.6 mm	179.39 mm	95.25 mm	49.21 mm	2602N
1150400EG	100	114 mm	192.5 mm	100.9 mm	48.9 mm	2890N
1150500EG	125	140 mm	232.7 mm	120 mm	57.1 mm	4450N
1150600EG	150	165 mm	286.6 mm	160.4 mm	84.1 mm	4450N
1150800EG	200	219 mm	327.1 mm	175.1 mm	73.4 mm	4450N

Table 2/2

Catalog Number	Certifications
1150050EG	UL, cUL
1150075EG	UL, FM Approved, Pipe Hanger Components, cUL
1150100EG	UL, FM Approved, Pipe Hanger Components, cUL
1150125EG	UL, FM Approved, Pipe Hanger Components, cUL
1150150EG	UL, FM Approved, Pipe Hanger Components, cUL
1150200EG	UL, FM Approved, Pipe Hanger Components, cUL

Catalog Number	Certifications
1150250EG	UL, FM Approved, Pipe Hanger Components, cUL
1150300EG	UL, FM Approved, Pipe Hanger Components, cUL
1150350EG	UL, FM Approved, Pipe Hanger Components, cUL
1150400EG	UL, FM Approved, Pipe Hanger Components, cUL
1150500EG	UL, FM Approved, Pipe Hanger Components, cUL
1150600EG	UL, FM Approved, Pipe Hanger Components, cUL
1150800EG	UL, FM Approved, Pipe Hanger Components, cUL

DIAGRAMS

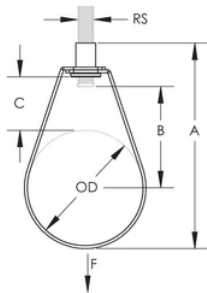

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

