

125 Weldable Insulation Shield



FEATURES

Distributes load of pipe evenly to eliminate or reduce insulation compression, and risk of crushing at the hanger point

Conforms with Federal Specification WW-H-171 (Type 41), Manufacturers Standardization Society ANSI®/MSS SP58 (Type 40)

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/1


Catalog Number	Outer Diameter (OD)	Length (L)	Thickness (T)
1250200EG	63.5 mm	304.8mm	1.3 mm
1250500EG	141.3 mm	304.8mm	1.3 mm
1250400EG	117.5 mm	304.8mm	1.3 mm
1250350EG	104.8 mm	304.8mm	1.3 mm
1250150EG	54 mm	304.8mm	1.3 mm
1250250EG	76.2 mm	304.8mm	1.3 mm

Catalog Number	Outer Diameter (OD)	Length (L)	Thickness (T)
1250300EG	92.1 mm	304.8mm	1.3 mm
1251000EG	273.1 mm	457.2mm	1.6 mm
1250600EG	168.3 mm	304.8mm	1.6 mm
1250800EG	212.7 mm	304.8mm	1.6 mm
1251200EG	323.9 mm	609.6mm	2 mm

ADDITIONAL PRODUCT DETAILS

Install in accordance with applicable code.

DIAGRAMS

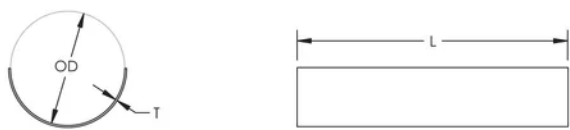

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

