

# 150M Standard U-Bolt



## FEATURES

Pipe support for general piping applications

Comes complete with 4 nuts (2 installed on each end)

Conforms with Federal Specification WW-H-171 (Type 24), Manufacturers Standardization Society ANSI®/MSS-SP-58 (Type 24)

## SPECIFICATIONS

**Finish:** Electrogalvanized


**Material:** Steel

Table 1/1

| Catalog Number | Outer Diameter (OD) | Screw Length (L) | A         | B       | Static Load |
|----------------|---------------------|------------------|-----------|---------|-------------|
| 150M0100EG     | 33.4 mm             | 60.5mm           | 93.7 mm   | 39.8 mm | 1930N       |
| 150M0125EG     | 42.2 mm             | 60.5mm           | 104.8 mm  | 51.7 mm | 4800N       |
| 150M0150EG     | 48.3 mm             | 63.5mm           | 109.6 mm  | 57.8 mm | 4800N       |
| 150M0200EG     | 60.3 mm             | 63.5mm           | 122.38 mm | 69.9 mm | 4800N       |
| 150M0250EG     | 73 mm               | 76.2mm           | 146.1 mm  | 85.7 mm | 8900N       |

| Catalog Number | Outer Diameter (OD) | Screw Length (L) | A        | B        | Static Load |
|----------------|---------------------|------------------|----------|----------|-------------|
| 150M0300EG     | 88.9 mm             | 76.2mm           | 160.3 mm | 101.6 mm | 8900N       |
| 150M0400EG     | 114.3 mm            | 76.2mm           | 185.7 mm | 127 mm   | 8950N       |
| 150M0500EG     | 141.3 mm            | 76.2mm           | 211.1 mm | 154 mm   | 8950N       |
| 150M0600EG     | 168.3 mm            | 95.3mm           | 257.1 mm | 184.2 mm | 14350N      |
| 150M0800EG     | 219.1 mm            | 95.3mm           | 308 mm   | 235 mm   | 14350N      |
| 150M1000EG     | 273.1 mm            | 101.6mm          | 369.8 mm | 292.1 mm | 21450N      |
| 150M1200EG     | 323.9 mm            | 108mm            | 430.1 mm | 346.1 mm | 29900N      |

## DIAGRAMS

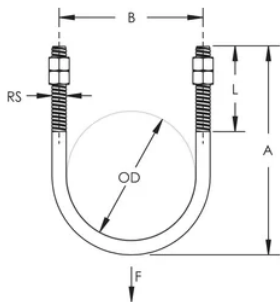

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

