

327 Malleable Iron Side Beam Attachment



FEATURES

Pre-threaded structural attachment fastened to wall or the side of a joist to support hanger rod where two #43 Wood Drive Screws are necessary for proper support

SPECIFICATIONS

Material: Steel

Table 1/1


Catalog Number	Finish	A	B	Static Load
3270037EG	Electrogalvanized	60.33 mm	23.81 mm	1100N
3270037PL	Plain	60.33 mm	23.81 mm	1100N
3270050PL	Plain	69.85 mm	33.34 mm	2130N
3270050EG	Electrogalvanized	69.85 mm	33.34 mm	2130N

ADDITIONAL PRODUCT DETAILS

Load rating dependent on wood structure strength.

Follow fastener manufacturer's recommended shear and pull-out strength when fastening to the structure. Fastener not included.

DIAGRAMS

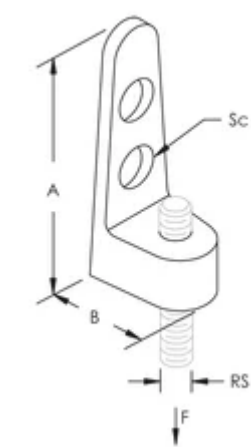

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

