

402 Clevis Hanger for Copper Tube, Light Duty



FEATURES

Recommended for the suspension of stationary non-insulated copper tube lines

Conforms with U.S. Federal Specification WW-H-171 (Type 12), Manufacturers Standardization Society (MSS) SP-58 (Type 1)

SPECIFICATIONS

Finish: Copper Electroplated


Material: Steel

Table 1/1

Catalog Number	Outer Diameter (OD)	A	B	C	Static Load
4020050CP	15.9 mm	52.39 mm	25.4 mm	6.35 mm	956N
4020075CP	18.9 mm	58.74 mm	31.75 mm	6.35 mm	956N
4020100CP	28.6 mm	76.2 mm	33.34 mm	14.29 mm	956N
4020125CP	34.9 mm	69.85 mm	44.45 mm	14.29 mm	956N
4020150CP	41.3 mm	84.14 mm	52.39 mm	19.05 mm	956N
4020200CP	54 mm	103.19 mm	61.91 mm	25.4 mm	956N

Catalog Number	Outer Diameter (OD)	A	B	C	Static Load
4020250CP	66.7 mm	122.24 mm	73.03 mm	26.99 mm	1100N
4020300CP	79.4 mm	139.7 mm	82.55 mm	28.57 mm	1334N
4020400CP	104.8 mm	171.45 mm	103.19 mm	39.69 mm	1957N

DIAGRAMS

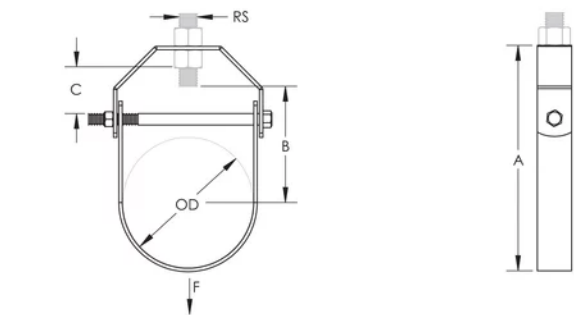

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

