

# 801 Standard Pipe Stay



## FEATURES

Used for water, heat or gas lines

## SPECIFICATIONS


**Finish:** Epoxy Powder Coated

**Material:** Steel

Table 1/1

Catalog Number	Outer Diameter (OD)	Copper Tube Size	Hole Size (HS)	A	B
801037050EP	17.4 mm	1/2"	7.9 mm	57.15 mm	44.45 mm
801050075EP	23.4 mm	3/4"	7.9 mm	57.15 mm	44.45 mm
801075100EP	29.6 mm	1"	7.9 mm	65.09 mm	50.8 mm
801100125EP	36 mm	1 1/4"	7.9 mm	65.09 mm	50.8 mm
801125150EP	44 mm	1 1/2"	7.9 mm	107.95 mm	76.2 mm
801150000EP	49.6 mm		7.9 mm	107.95 mm	76.2 mm

DIAGRAMS

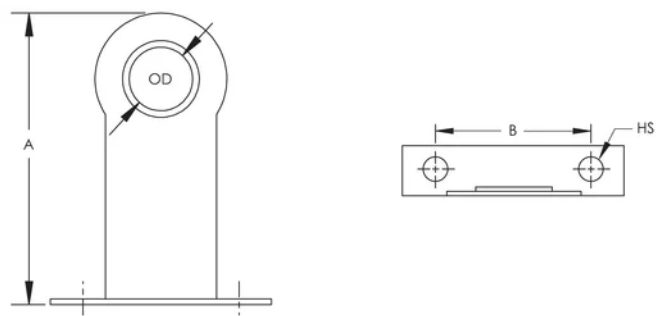

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

