

B18-SBT Box/Multiple Conduit Hanger



The nVent CADDY B18-SBT Box/Multiple Conduit Hanger presents an efficient and secure solution for the installation of electrical boxes and conduit in overhead applications. With a wide range of box, conduit and MC/AC cable configurations, the Combination Box/Conduit is built to accommodate both simple and complex job site challenges while creating a robust mounting system that features multiple tool-free conduit securement options.

FEATURES

Scoreline breakaway feature can be easily modified by hand while maintaining UL listing

Eliminates need for offset bending conduit

Labor and time savings due to built-in first means of support

NEC® and CEC compliant

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/1

Catalog Number	Hole Size (HS)	Length (L)	Width (W)
B18SBT18	6.4 mm	604.52mm	91.44 mm
B18SBT18TI	6.4 mm	604.52mm	91.44 mm


ADDITIONAL PRODUCT DETAILS

TI letters in the part number stands for "Thread Impression"

NEC® 300.11 requires dedicated drop wire/rod. For single and multiple runs of conduit.

Hole Size value refers to mounting hole.

DIAGRAMS

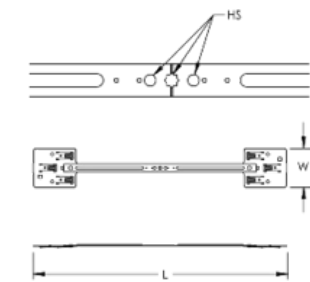

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

