

Bolt Close Pipe Clamp for Copper Tube



FEATURES

Retained bolt and built-in nut means there are less parts to handle or drop

Combo head bolt works with slotted, hex, #3 phillips or #2 robertson drivers

SPECIFICATIONS

Finish: Copper Electroplated


Material: Steel

Table 1/1

Catalog Number	Copper Tube Size	Hole Size (HS)	Static Load
CD3BCP	1 1/2"	6.4 mm	1550N
CD2BCP	1"	6.4 mm	1100N
CD2.5BCP	1 1/4"	6.4 mm	1100N
CD1BCP	3/4"	6.4 mm	1100N
CD0BCP	1/2"	6.4 mm	1100N
CD5BCP	2"	7.9 mm	1550N

Catalog Number	Copper Tube Size	Hole Size (HS)	Static Load
CD2.5B37CP	1 1/4"	9.5 mm	1100N
CD0B37CP	1/2"	9.5 mm	1100N
CD5B37CP	2"	9.5 mm	1550N
CD3B37CP	1 1/2"	9.5 mm	1550N
CD2B37CP	1"	9.5 mm	1100N
CD1B37CP	3/4"	9.5 mm	1100N

DIAGRAMS

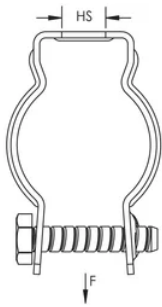

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

