


EM-M Conduit/Pipe to Flange Clip



CERTIFICATIONS

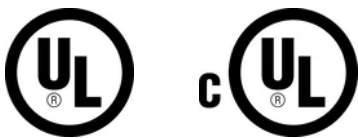

FEATURES

Supports conduit/pipe or cable from beam flanges

Snap close clip pivots a full 360°

Requires only a hammer to install

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	Outer Diameter (OD)	Flange Thickness (FT)	Static Load	Certifications
16M24	23.4 - 35 mm	3 - 8 mm	330N	
20M24	35 - 42 mm	3 - 8 mm	330N	
24M24	42 - 50 mm	3 - 8 mm	330N	

Catalog Number	Outer Diameter (OD)	Flange Thickness (FT)	Static Load	Certifications
32M24	50 - 60 mm	3 - 8 mm	330N	
6M24	14 - 18 mm	3 - 8 mm	330N	
812M24	18 - 30 mm	3 - 8 mm	330N	
16M58	23.4 - 35 mm	8 - 14 mm	330N	
20M58	35 - 42 mm	8 - 14 mm	330N	
24M58	42 - 50 mm	8 - 14 mm	330N	
32M58	50 - 60 mm	8 - 14 mm	330N	
6M58	14 - 18 mm	8 - 14 mm	330N	
812M58	18 - 30 mm	8 - 14 mm	330N	
6M912	14 - 18 mm	14 - 20 mm	330N	
812M1318	18 - 30 mm	21 - 28 mm	330N	UL, cUL
812M912	18 - 30 mm	14 - 20 mm	330N	
16M912	23.4 - 35 mm	14 - 20 mm	330N	
20M912	35 - 42 mm	14 - 20 mm	330N	
24M912	42 - 50 mm	14 - 20 mm	330N	UL, cUL
32M912	50 - 60 mm	14 - 20 mm	330N	

DIAGRAMS

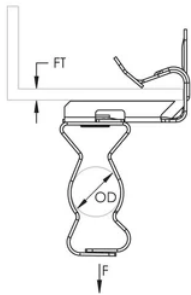

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

