

# HangerMate® Horizontal Mount Screw for Steel



## FEATURES

Convenient design allows fast and easy installation

Eliminates the need for labor-intensive operations, such as pre-punching or drilling of steel components

Only one driver needed for all anchor sizes


Cross-drilled and tapped head permits horizontal mounting of threaded rod systems

## SPECIFICATIONS

Table 1/1

Catalog Number	Material	Finish	Flange Thickness (FT)	Screw Length (L)
HMZH475	Steel	Electrogalvanized	1.5 - 6.4 mm	25.4mm

## DIAGRAMS

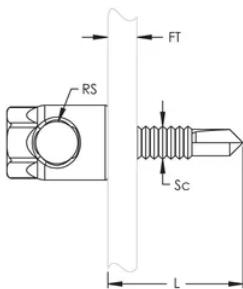

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

