

Improved nVent CADDY Cat HP J-Hook Mod Clip with BC200 Beam Clamp, Swivel



The Improved nVent CADDY Cat HP Mod Clip J-Hook with BC200 Swivel Beam Clamp simplifies beam flange installation while adding the ability to rotate 360 degrees. By eliminating the need for screws, rivets or special tools during assembly, installation time and cost is reduced. A simple clip onto nVent CADDY Cat HP components ensures a secure hold—ultimately enhancing rigidity and stability while minimizing inventory impact and providing flexibility on the job site.

CERTIFICATIONS



FEATURES


Rotates 360 degrees to support various directional runs of cable

Works with nVent J-Hook Versa-Mount technology from nVent CADDY

SPECIFICATIONS

Table 1/1				
Catalog Number	Finish	Material	Flange Thickness (FT)	Static Load
CATHPMBBC200B	Electrogalvanized, nVent CADDY Armour	Steel, Spring Steel	3.175 - 15.875 mm	445kg

DIAGRAMS

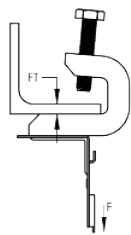

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

