


Improved nVent CADDY Cat HP J-Hook Mod Clip with Hammer-On Flange Clip, Swivel

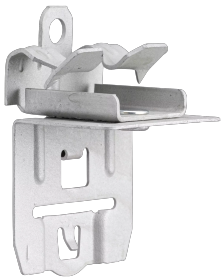

The Improved nVent CADDY Cat HP J-Hook Mod Clip with Hammer-On Flange Clip, Swivel combines the ease of hammer-on installation without the need for screws or rivets and features a 360-degree rotation for versatile cable routing. This stable cable management solution provides ultimate flexibility on the job and while minimizing inventory impact.

CERTIFICATIONS



FEATURES

Requires only a hammer to install

Works with nVent J-Hook Versa-Mount technology from nVent CADDY


SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/1

Catalog Number	Flange Thickness (FT)	Static Load
CATHPM24	3.18 - 6.35 mm	334kg
CATHPM58	8.0 - 12.7 mm	334kg
CATHPM912	12.70 - 19.05 mm	334kg

 

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

