



# Improved nVent CADDY Cat HP J-Hook Mod Clip with Shot-Fire Bracket

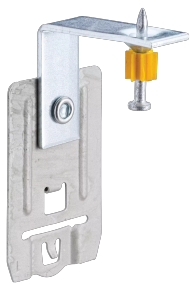

Improved nVent CADDY Cat HP Mod Clip J-Hook Bracket with Shot-Fire Bracket simplifies cable management with color-coded options for easy pathway identification and rapid attachment to various surfaces. The bracket allows for customizable cable routing configurations while ensuring compatibility with nVent CADDY Cat HP components of any size—making it a trusted choice in the field.

## CERTIFICATIONS

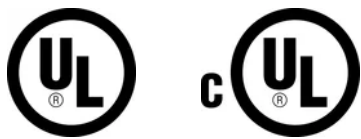


## FEATURES

- Complete with nVent CADDY Cat HP J-Hook with Shot-Fire Bracket and pre-assembled drive pin from DEWALT®
- Works with nVent J-Hook Versa-Mount technology from nVent CADDY
- Quickly and easily attaches to concrete, steel or composite metal decking
- Integrated pin installs easily using powder-actuated or single-shot gas-actuated tools
- ICC-ES ESR-2024 evaluation report available for drive pin from DEWALT® ready-to-go out of the box

## SPECIFICATIONS

| Table 1/1      |                                       |                     |           |             |           |
|----------------|---------------------------------------|---------------------|-----------|-------------|-----------|
| Catalog Number | Finish                                | Material            | A         | Static Load | Width (W) |
| CATHPMABSF     | Electrogalvanized, nVent CADDY Armour | Steel, Spring Steel | 39.688 mm | 267kg       | 46.99 mm  |

DIAGRAMS

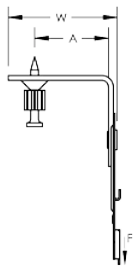

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

