

Lathers Channel to Rod/Wire Clip, Side Mount



CERTIFICATIONS



FEATURES

Provides pre-leveling of channel

No tools required for installation

Use with plain rod or wire

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel


Table 1/1

Catalog Number	Lathers Channel Height (H)	Lathers Channel Width (W)	Wire Size	Static Load
4B2LS	50.8mm	11.1 - 15.9 mm	1 mm Min	700N
4B15LS	38.1mm	11.1 - 15.9 mm	1 mm Min	880N

ADDITIONAL PRODUCT DETAILS

4B15LS meets NYC Building Code for 280lb load rating (see PE letter in Resources tab).

DIAGRAMS

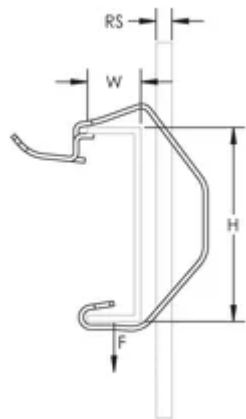

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

