

nVent CADDY All-in-One Floor-Mounted With Adjustable Mud Ring



CERTIFICATIONS



FEATURES

Preset to a finish height of 18 in from the floor (adjustable to 12 or 15 in)

Adjustable mud ring accommodates various thicknesses of drywall

Can be adjusted after the installation of drywall

Box remains fixed in place when mud ring is removed

Integrated first means of support accepts conduit or MC/AC cable

Accommodates additional nVent CADDY All-in-One box assemblies, support brackets and low-voltage mounting plates

Includes multiple 1/2 and 3/4 in knockouts on each side of the box

SPECIFICATIONS

Knockout Sizes: (8) 12.7 mm, 19.1 mm;(3) 12.7 mm

Finish: Pregalvanized

Material: Steel

Table 1/2

Catalog Number	Gang	Ground Wire Included	Box Volume	Drywall Thickness	Depth (D)	A
A1FFV1G	1	Yes	537cm ³	19.1 - 38.1 mm	92.1mm	563.6 mm
A1FFV2G	2	Yes	537cm ³	15.9 - 38.1 mm	92.1mm	563.6 mm


Table 2/2

Catalog Number	B	C
A1FFV1G	196.9 mm	68.3 mm
A1FFV2G	196.9 mm	68.3 mm

ADDITIONAL PRODUCT DETAILS

Ground wire pigtail is 10".

DIAGRAMS

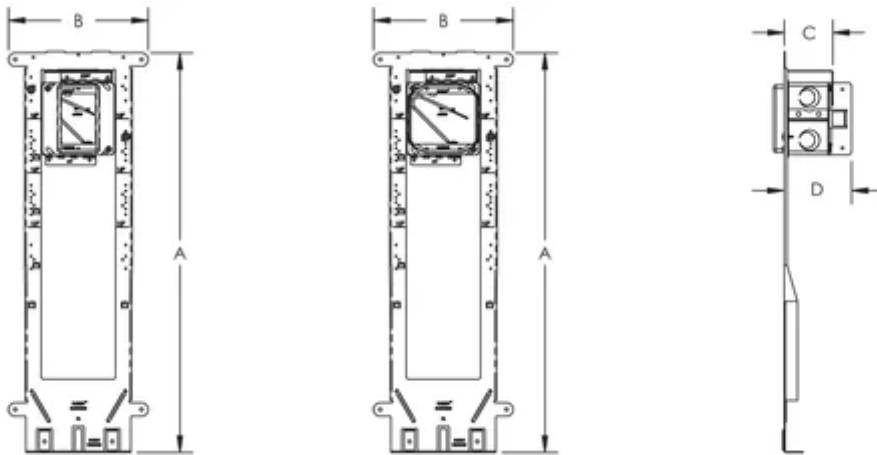

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

