


nVent CADDY All-in-One Stud-Mounted With Removable Mud Ring

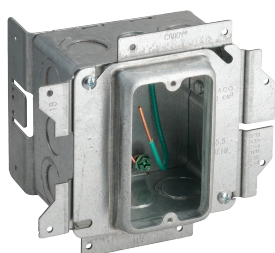

CERTIFICATIONS



FEATURES

Removable mud ring provides front access to the interior of the box

Box remains fixed in place when mud ring is removed

Includes multiple knockouts on each side of the box

Assemblies keyed for precise alignment when installed on both sides of a stud

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2

Catalog Number	Knockout Sizes	Gang	Ground Wire Included	Back Plate Pre-assembled	Box Volume	Drywall Thickness
A1SF1G	(8) 12.7 mm, 19.1 mm	1	Yes	Yes	537cm ³	15.9 mm

CatalogNumber	Knockout Sizes	Gang	Ground Wire Included	Back Plate Pre-assembled	Box Volume	Drywall Thickness
A1SF2G	(8) 12.7 mm, 19.1 mm	2	Yes	Yes	537cm ³	15.9 mm
A1SF1GS	(8) 12.7 mm, 19.1 mm	1	Yes	Yes	537cm ³	15.9 mm
A1SD1N	(1) 12.7 mm, (3) 25.4 mm, (5) 12.7 mm, 19.1 mm	1	No	Yes	537cm ³	15.9 mm


Table 2/2

Catalog Number	Depth (D)	A	B
A1SF1G	92.1mm	146.05 mm	130.18 mm
A1SF2G	92.1mm	146.05 mm	130.18 mm
A1SF1GS	63.5mm	146.05 mm	130.18 mm
A1SD1N	92.1mm	146.05 mm	130.18 mm

ADDITIONAL PRODUCT DETAILS

Ground wire pigtail is 10".

DIAGRAMS

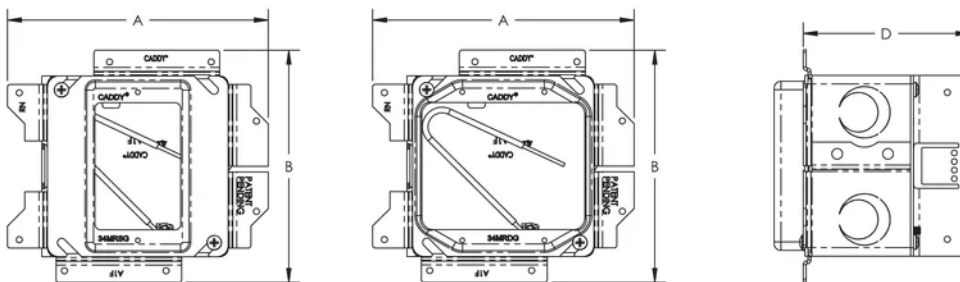

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

