

nVent CADDY Cablecat J-Hook



CERTIFICATIONS



FEATURES

Many sizes and designs available to attach to a variety of structures

Cost effective alternative to expensive cable tray

Galvanized finish on J-Hooks provide smoother cable pull and greater corrosion resistance

cULus® Listed and complies with NEC® and TIA requirements for structured cabling systems

SPECIFICATIONS


Table 1/2

Catalog Number	Material	Finish	Diameter (Ø)	Height (H)	Cable Capacity, Cat 5e	Cable Capacity, Cat 6
CAT12	Steel	Pregalvanized	19.1 mm	80.3 mm	16	10

Table 2/2

Catalog Number	Area
CAT12	387.1mm ²

DIAGRAMS

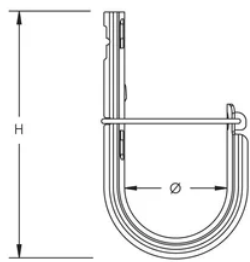

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

