

nVent CADDY Cablecat J-Hook with BC200 Beam Clamp, Swivel



CERTIFICATIONS



FEATURES

Beam clamp with attached nVent CADDY Cablecat J-Hook

Supports low voltage cables


Rotates 360 degrees to support various directional runs of cable

SPECIFICATIONS

Table 1/1

Catalog Number	Material	Finish	Diameter (Ø)	Flange Thickness (FT)
CAT12BC200B	Steel	Pregalvanized	19 mm	3 - 12 mm

DIAGRAMS

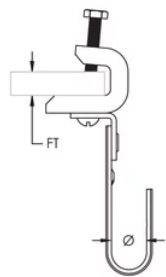

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

