

nVent CADDY Cat HP J-Hook Tree, Ceiling Mount



FEATURES

Ideal for attaching to concrete, steel or wood surfaces

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Ready to use out of the box, saving installation time and labor

Requires no screws, rivets or special tools for assembly

Single- or double-sided tree configurations provide multiple J-Hooks with one structural attachment

Provides superior fill capacity and load rating over most other non-continuous cable support alternatives

Complies with EN 50174-2

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2

Catalog Number	Type	Diameter (Ø)	Tiers	Height (H)	Width (W)	Hole Size 1 (HS1)
CAT32HPDCM2	Double Sided	50 mm	2	260 mm	148 mm	10.3 mm
CAT32HPDCM3	Double Sided	50 mm	3	387 mm	148 mm	10.3 mm

CatalogNumber	Type	Diameter (Ø)	Tiers	Height (H)	Width (W)	Hole Size 1 (HS1)
CAT32HPDCM4	Double Sided	50 mm	4	514 mm	148 mm	10.3 mm
CAT32HPSCM2	Single Sided	50 mm	2	260 mm	84.8 mm	10.3 mm
CAT32HPSCM3	Single Sided	50 mm	3	387 mm	84.8 mm	10.3 mm
CAT32HPSCM4	Single Sided	50 mm	4	514 mm	84.8 mm	10.3 mm
CAT64HPDCM2	Double Sided	100 mm	2	387 mm	254 mm	10.3 mm
CAT64HPDCM3	Double Sided	100 mm	3	578 mm	254 mm	10.3 mm
CAT64HPDCM4	Double Sided	100 mm	4	768 mm	254 mm	10.3 mm
CAT64HPSCM2	Single Sided	100 mm	2	387 mm	138 mm	10.3 mm
CAT64HPSCM3	Single Sided	100 mm	3	578 mm	138 mm	10.3 mm
CAT64HPSCM4	Single Sided	100 mm	4	768 mm	138 mm	10.3 mm

Table 2/2

Catalog Number	Hole Size 2 (HS2)	A	B	Static Load 1 (F1)	Static Load 2 (F2)
CAT32HPDCM2	4.7 mm	36.5 mm	50 mm	1080N	810N
CAT32HPDCM3	4.7 mm	36.5 mm	50 mm	1620N	810N
CAT32HPDCM4	4.7 mm	36.5 mm	50 mm	2160N	810N
CAT32HPSCM2	4.7 mm	36.5 mm	50 mm	540N	540N
CAT32HPSCM3	4.7 mm	36.5 mm	50 mm	810N	810N
CAT32HPSCM4	4.7 mm	36.5 mm	50 mm	1080N	810N
CAT64HPDCM2	4.7 mm	36.5 mm	50 mm	1080N	810N

Catalog Number	Hole Size 2 (HS2)	A	B	Static Load 1 (F1)	Static Load 2 (F2)
CAT64HPDCM3	4.7 mm	36.5 mm	50 mm	1620N	810N
CAT64HPDCM4	4.7 mm	36.5 mm	50 mm	2160N	810N
CAT64HPSCM2	4.7 mm	36.5 mm	50 mm	540N	540N
CAT64HPSCM3	4.7 mm	36.5 mm	50 mm	810N	810N
CAT64HPSCM4	4.7 mm	36.5 mm	50 mm	1080N	810N


ADDITIONAL PRODUCT DETAILS

Static loads represent maximum load limit of J-Hook tree. Static load limit of each J-Hook is 60 lb (270 N).

Refer to Static Load 1 when fastening J-Hook tree using Hole Size 1. Refer to Static Load 2 when fastening J-Hook tree using Hole Size 2.

Non-continuous supports may not exceed spacing of 5' (1.5 m) per TIA 569-C.9.7 and EN 50174-2.

DIAGRAMS

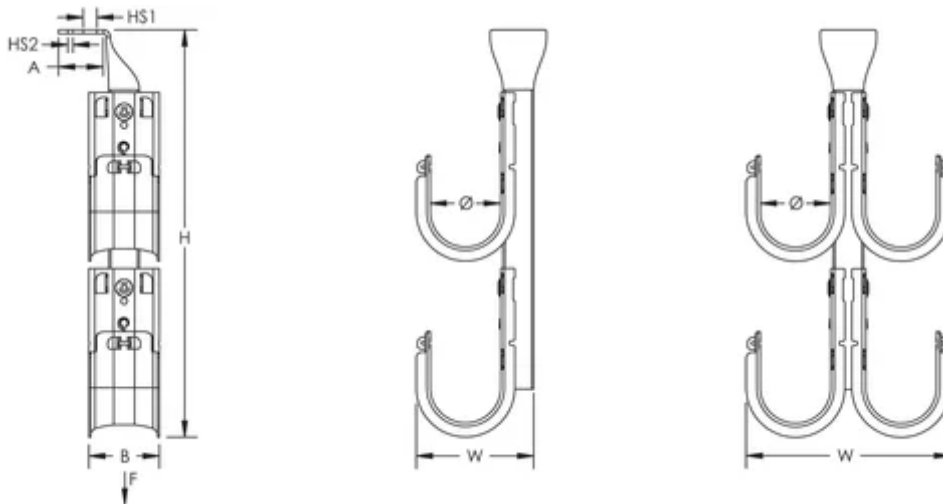

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

