

nVent CADDY Macrofix Plus NI EZ with Easy Closure



CERTIFICATIONS



FEATURES

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

SPECIFICATIONS


Finish: Electrogalvanized

Material: Steel

Table 1/1

Catalog Number	Outer Diameter (OD)	Width (W)	Thickness (T)	Static Load	Certifications
4290050EG	20.0 - 21.3 mm	30.2 mm	1.59 mm	1100N	cUL, UL
4290075EG	25.0 - 26.9 mm	30.2 mm	1.59 mm	1100N	cUL, UL, FM Approved, Pipe Hanger Components
4290100EG	32.0 - 33.7 mm	30.2 mm	1.59 mm	1100N	FM Approved, Pipe Hanger Components, cUL, UL
4290125EG	40.0 - 42.4 mm	30.2 mm	1.59 mm	1100N	cUL, UL, FM Approved, Pipe Hanger Components
4290150EG	48.3 - 50 mm	30.2 mm	1.98 mm	1420N	FM Approved, Pipe Hanger Components, cUL, UL
4290200EG	60.3 - 63 mm	30.2 mm	1.98 mm	1420N	cUL, UL, FM Approved, Pipe Hanger Components
4290250EG	73.0 - 76.1 mm	30.2 mm	1.98 mm	1420N	cUL, UL
4290300EG	88.9 - 90 mm	30.2 mm	1.98 mm	1690N	cUL, UL
4290400EG	110.0 - 114.3 mm	30.2 mm	2.38 mm	1957N	cUL, UL
4290500EG	139.7 - 141.3 mm	30.2 mm	2.38 mm	1957N	

DIAGRAMS

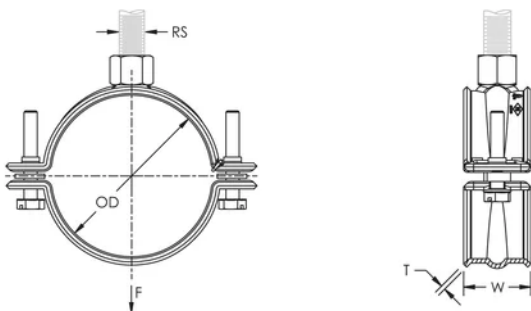

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

