

nVent CADDY Pyramid EZ Rubber-Based Support



FEATURES

No tools or fasteners needed; fast snap-on installation

Design sheds water and helps reduce pipe corrosion

Roof-friendly; made of UV-stabilized EPDM material

SPECIFICATIONS

Table 1/2

Catalog Number	Material	NB/DN	Outer Diameter (OD)	Height (H)	Length (L)	Width (W)
RPSE1H	EPDM-SBR Rubber	25	33 mm	25.4 mm	102mm	55.9 mm


Table 2/2

Catalog Number	Unit Weight	Ultimate Static Load (F)
RPSE1H	0.24 kg	756N

ADDITIONAL PRODUCT DETAILS

Ultimate load at 1/4" (6.35 mm) deflection. Contact project or roofing engineer for maximum allowable load on individual project roof system.

DIAGRAMS

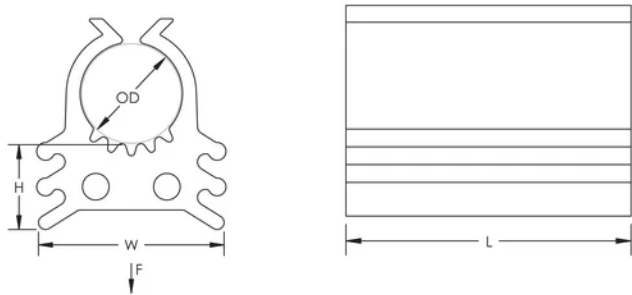

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

