

nVent CADDY Slick Nut



FEATURES

Provides fast universal attachment of threaded rod and hardware to standard strut profiles

SPECIFICATIONS

Finish: nVent CADDY Armour
Material: Polyamide;Spring Steel

Table 1/2

Catalog Number	Hole Size (HS)	Hole Type	Height (H)	Torque (TQ)	Static Load 1 (F1)	Static Load 2 (F2)
SLICK250	0.25 mm	Threaded	17 mm	5 N·m	1800N	450N
SLICK375	0.375 mm	Threaded	17 mm	13.5 N·m	2668N	450N
SLICK500	0.5 mm	Threaded	17.5 mm	13.5 N·m	2668N	445N

Table 2/2

Catalog Number	Static Load 3 (F3)
SLICK250	1100N
SLICK375	1110N


Catalog Number	Static Load 3 (F3)
SLICK500	1100N

ADDITIONAL PRODUCT DETAILS

Indicated loads are independent of the threaded stud or rod.

Indicated loads are applicable on 14 GA and 12 GA (2 mm and 2.5 mm) strut channels only.

DIAGRAMS

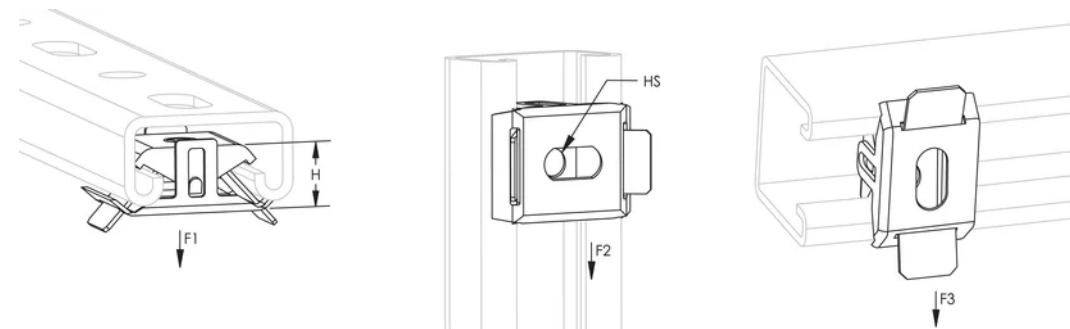

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

