

nVent CADDY Superklip



FEATURES

Closes and locks automatically when the pipe, tube or cable is inserted

One-piece clamp for fast and convenient installation

Fasten with either wood screw, dual threaded screw with or without collar, nail with collar, threaded rod, mounting plate or shot-fire bracket

SPECIFICATIONS

Temperature: -25 to 90 °C


Material: Xenoy®

Table 1/1

Catalog Number	Outer Diameter (OD)	Copper Tube Size	B	C	Static Load
389017	7.8 - 9.5 mm	1/4"	17.1 mm	26.4 mm	135N
389018	9.5 - 11.8 mm	1/4"	17.1 mm	26.4 mm	150N
389003	16.8 - 19.5 mm	5/8"	20 mm	35.4 mm	190N
389001	11.8 - 14.3 mm	3/8"	17.2 mm	29.9 mm	160N
389004	19.5 - 21.8 mm		20 mm	39.4 mm	200N

Catalog Number	Outer Diameter (OD)	Copper Tube Size	B	C	Static Load
389002	14.3 - 16.8 mm	1/2"	19.5 mm	32 mm	175N
389005	21.8 - 24.8 mm	3/4"	20 mm	42 mm	215N
389007	27.8 - 31.2 mm	1"	20.2 mm	48.9 mm	260N
389006	24.8 - 27.8 mm		20.2 mm	45.1 mm	240N
389008	31.2 - 35.5 mm	1 1/4"	21 mm	54.4 mm	300N
389009	35.5 - 39.5 mm	1 1/4"	21 mm	59.4 mm	320N
389012	46.5 - 50.5 mm		22 mm	72.8 mm	375N
389011	39.5 - 43.5 mm	1 1/2"	21 mm	64.2 mm	360N
389013	50.5 - 55.5 mm	2"	23 mm	78.7 mm	400N
389014	58.5 - 64 mm		23.2 mm	88.2 mm	410N

DIAGRAMS

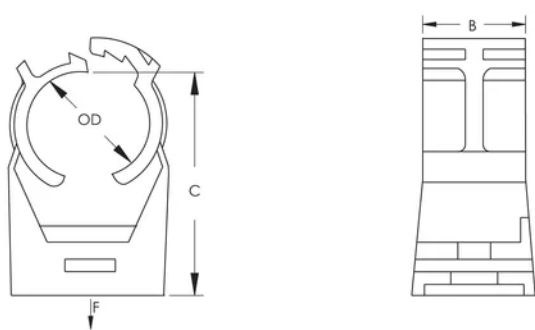

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

