

RIGD Single Piece Strut Clamp for Pipe/Rigid Conduit



CERTIFICATIONS



FEATURES

One piece break apart strut clamp (1/2" thru 4" pipe size)

Includes thread impression and captured screw (1/2" thru 4" pipe size)

Fits into open side of strut channel

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 59)

SPECIFICATIONS


Table 1/1

Catalog Number	Material	Finish	Outer Diameter (OD)	Width (W)	Thickness (T)	Static Load
RIGD0050EG	Steel	Electrogalvanized	21.3 mm	31.8 mm	2 mm	1779N
RIGD0050S4	Stainless Steel 304 (EN 1.4301)		21.3 mm	31.8 mm	2 mm	1779N

CatalogNumber	Material	Finish	Outer Diameter (OD)	Width (W)	Thickness (T)	Static Load
RIGD0075EG	Steel	Electrogalvanized	26.7 mm	31.8 mm	2 mm	2670N
RIGD0075S4	Stainless Steel 304 (EN 1.4301)		26.7 mm	31.8 mm	2 mm	2670N
RIGD0100EG	Steel	Electrogalvanized	33.4 mm	31.8 mm	2 mm	2670N
RIGD0100S4	Stainless Steel 304 (EN 1.4301)		33.4 mm	31.8 mm	2 mm	2670N
RIGD0125EG	Steel	Electrogalvanized	42.2 mm	31.8 mm	2 mm	2670N
RIGD0125S4	Stainless Steel 304 (EN 1.4301)		42.2 mm	31.8 mm	2 mm	2670N
RIGD0150EG	Steel	Electrogalvanized	48.3 mm	31.8 mm	2.8 mm	3550N
RIGD0150S4	Stainless Steel 304 (EN 1.4301)		48.3 mm	31.8 mm	2.8 mm	3550N
RIGD0200EG	Steel	Electrogalvanized	60.3 mm	31.8 mm	2.8 mm	3550N
RIGD0200S4	Stainless Steel 304 (EN 1.4301)		60.3 mm	31.8 mm	2.8 mm	3550N
RIGD0250EG	Steel	Electrogalvanized	73 mm	31.8 mm	2.8 mm	3550N
RIGD0250S4	Stainless Steel 304 (EN 1.4301)		73 mm	31.8 mm	2.8 mm	3550N
RIGD0300EG	Steel	Electrogalvanized	88.9 mm	31.8 mm	2.8 mm	3550N
RIGD0300S4	Stainless Steel 304 (EN 1.4301)		88.9 mm	31.8 mm	2.8 mm	3550N
RIGD0350EG	Steel	Electrogalvanized	101.6 mm	31.8 mm	3 mm	3500N
RIGD0400EG	Steel	Electrogalvanized	114.3 mm	31.8 mm	3 mm	3500N

CatalogNumber	Material	Finish	Outer Diameter (OD)	Width (W)	Thickness (T)	Static Load
RIGD0400S4	Stainless Steel 304 (EN 1.4301)		114.3 mm	31.8 mm	3 mm	3500N

DIAGRAMS

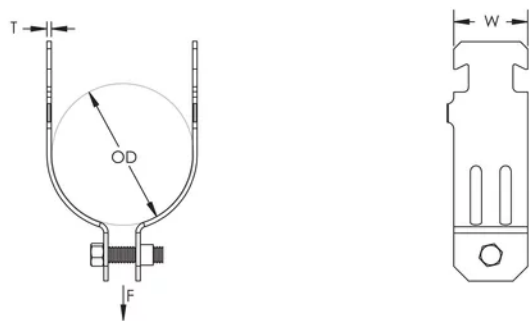

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

