

Snap Close Conduit/Pipe Clamp



The nVent CADDY Snap Close Conduit Clamps (M-Series) are a fast and efficient method to secure conduit branch circuits for electrical installations. The M-Series is designed to provide positional consistency in application by eliminating conduit offset as well as maintain spacing entering electrical boxes. Increase installation efficiency by utilizing our comprehensive conduit range for your next electrical project.

CERTIFICATIONS



FEATURES

May be used for either vertical or horizontal installations

Eliminates need for offset bending conduit

Finger closure, no tools required

Locking design has greater resistance to twisting loads and is stronger than any on the market

Low profile locking tabs and smooth gripping dimples remove the possibility of scrapes

812M and 16M feature double tabs to center conduit, increase range and holding power and prevent conduit from sliding

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	Outer Diameter (OD)	Hole Size (HS)	Hole Type	Static Load 1 (F1)	Static Load 2 (F2)
16M4I	23.4 - 35 mm	6.4 mm	Threaded	440N	110N

Catalog Number	Outer Diameter (OD)	Hole Size (HS)	Hole Type	Static Load 1 (F1)	Static Load 2 (F2)
20M4I	35 - 42 mm	6.4 mm	Threaded	440N	110N
24M4I	42 - 50 mm	6.4 mm	Threaded	440N	110N
32M4I	50 - 60 mm	6.4 mm	Threaded	440N	110N
6M4I	14 - 18 mm	6.4 mm	Threaded	440N	110N
812M4I	18 - 30 mm	6.4 mm	Threaded	440N	110N
16M	23.4 - 35 mm	7 mm	Plain	440N	110N
20M	35 - 42 mm	7 mm	Plain	440N	110N
24M	42 - 50 mm	7 mm	Plain	440N	110N
32M	50 - 60 mm	7 mm	Plain	440N	110N
6M	14 - 18 mm	7 mm	Plain	440N	110N
812M	18 - 30 mm	7 mm	Plain	440N	110N

DIAGRAMS

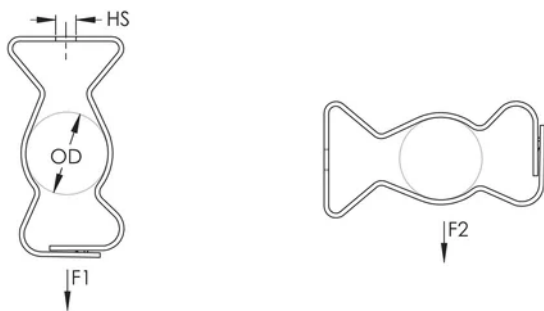

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

