

Strut and Rod Beam Clamp



CERTIFICATIONS



FEATURES

Multifunctional beam clamp suitable for strut channel or threaded rod

Bolt included


Requires installation in pairs

SPECIFICATIONS

Table 1/1

Catalog Number	Material	Finish	Strut Type	Flange Thickness (FT)	A	Static Load
STCB6	Steel	Electrogalvanized	A (41 x 41 mm), CC (41 x 41 mm)	50.8 mm Max	71 mm	1779N

DIAGRAMS

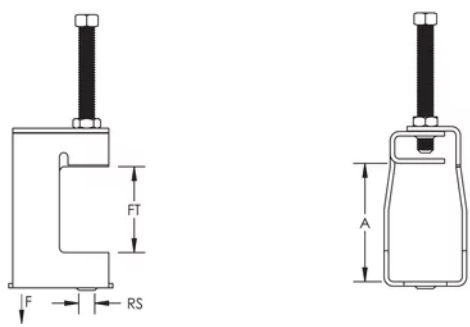

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

