

WBT Performance Cable Tray Independent Underfloor Support



The nVent CADDY WBT Performance Cable Tray Underfloor Support provides a reliable method for routing wire basket trays beneath the floor with independent structural support. This component is ideal for installations requiring low-voltage cabling to pass under cabinets or equipment.

Engineered for stability and simplicity, the underfloor support system eliminates the need for complex framing. It braces the tray directly beneath raised floors, allowing for clean, unobtrusive cable pathways that preserve floor space and reduce visual clutter. This is especially valuable in data centers, control rooms, and other high-density environments where cable organization and accessibility are critical.

The Support integrates seamlessly with the broader nVent CADDY WBT Performance Cable Tray System, ensuring compatibility with shaped and round wire tray profiles. Its design accommodates standard fasteners and finishes, including pre-galvanized, zinc electroplate, and powder coat options, making it adaptable to a wide range of project specifications.

FEATURES

Designed to be used with the nVent CADDY WBT Performance Cable Tray Washer Support and nVent CADDY WBT Performance Cable Tray Ground Splice

Maintains a fixed and secure distance from the ground to ensure safety and accessibility

Available in a range of sizes to match wire basket tray design

Fixed height ensures a level installation

SPECIFICATIONS


Finish: Pregalvanized

Material: Steel

Table 1/1

Catalog Number	Height (H)	Length (L)	Length 1 (L1)	Width (W)	Hole Size (HS)	Unit Weight
WBTUS04	32 mm	767mm	560.78 mm	235 mm	14.3 mm	0.862 kg
WBTUS06	32 mm	868mm	560.78 mm	235 mm	14.3 mm	0.953 kg
WBTUS24	32 mm	1778mm	560.78 mm	235 mm	14.3 mm	3.22 kg
WBTUS08	32 mm	965mm	560.78 mm	235 mm	14.3 mm	1.089 kg
WBTUS12	32 mm	1174mm	560.78 mm	235 mm	14.3 mm	1.588 kg
WBTUS18	32 mm	1474mm	560.78 mm	235 mm	14.3 mm	2.404 kg

DIAGRAMS

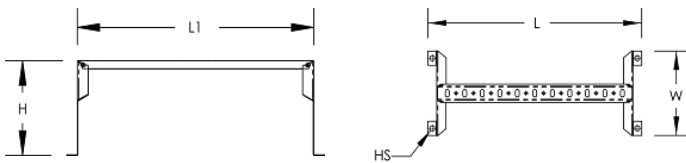

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

