


WBT Performance Cable Tray Polymer Insert

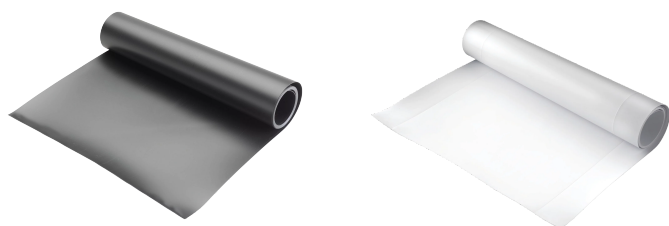

The nVent CADDY WBT Performance Cable Tray Polymer Insert utilizes a flame-retardant polymer to envelop the entire tray-providing bottom, side and cover protection. Available options include a flat bottom or a prescored version to the tray depth for coverage of the bottom and sides.

FEATURES

Standard black finish for use with divider posts

Polymer insert rolls into the tray bottom

Multiple color options to coordinate with cable tray selection

SPECIFICATIONS

Finish: N/A

Material: Polymer


Table 1/1

Catalog Number	Color	Height (H)	Width (W)	Length (L)	Sides Included	Unit Weight
WBTFORM04BA	Black		92.2 mm	3048mm	No	0.02 kg
WBTFORM06BA	Black		143 mm	3048mm	NoEFS_WBTFO RM06BA	0.03 kg
WBTFORM08BA	Black		193.8 mm	3048mm	NoEFS_WBTFO RM08BA	0.04 kg
WBTFORM2X4B A	Black	50.8 mm	92.2 mm	3048mm	Yes	0.04 kg

CatalogNumber	Color	Height (H)	Width (W)	Length (L)	Sides Included	Unit Weight
WBTFORM2X6B A	Black	50.8 mm	143 mm	3048mm	YesEFS_WBTFO RM2X6BA	0.05 kg
WBTFORM12BA	Black		295.4 mm	3048mm	NoEFS_WBTFO RM12BA	0.06 kg
WBTFORM2X8B A	Black	50.8 mm	193.8 mm	3048mm	YesEFS_WBTFO RM2X8BA	0.06 kg
WBTFORM4X4B A	Black	101.6 mm	92.2 mm	3048mm	YesEFS_WBTFO RM4X4BA	0.06 kg
WBTFORM4X6B A	Black	101.6 mm	143 mm	3048mm	Yes	0.07 kg
WBTFORM16BA	Black		397 mm	3048mm	No	0.08 kg
WBTFORM2X12 BA	Black	50.8 mm	295.4 mm	3048mm	Yes	0.08 kg
WBTFORM4X8B A	Black	101.6 mm	193.8 mm	3048mm	Yes	0.08 kg
WBTFORM18BA	Black		447.8 mm	3048mm	No	0.09 kg
WBTFORM20BA	Black		498.6 mm	3048mm	No	0.1 kg
WBTFORM2X16 BA	Black	50.8 mm	397 mm	3048mm	Yes	0.1 kg
WBTFORM4X12 BA	Black	101.6 mm	295.4 mm	3048mm	YesEFS_WBTFO RM4X12BA	0.1 kg
WBTFORM6X8B A	Black	152.4 mm	193.8 mm	3048mm	Yes	0.1 kg
WBTFORM2X18 BA	Black	50.8 mm	447.8 mm	3048mm	YesEFS_WBTFO RM2X18BA	0.11 kg
WBTFORM24BA	Black		600.2 mm	3048mm	No	0.12 kg

CatalogNumber	Color	Height (H)	Width (W)	Length (L)	Sides Included	Unit Weight
WBTFORM2X20 BA	Black	50.8 mm	498.6 mm	3048mm	Yes	0.12 kg
WBTFORM4X16 BA	Black	101.6 mm	397 mm	3048mm	YesEFS_WBTFO RM4X16BA	0.12 kg
WBTFORM6X12 BA	Black	152.4 mm	295.4 mm	3048mm	Yes	0.12 kg
WBTFORM4X18 BA	Black	101.6 mm	447.8 mm	3048mm	Yes	0.13 kg
WBTFORM2X24 BA	Black	50.8 mm	600.2 mm	3048mm	Yes	0.14 kg
WBTFORM4X20 BA	Black	101.6 mm	498.6 mm	3048mm	Yes	0.14 kg
WBTFORM6X16 BA	Black	152.4 mm	397 mm	3048mm	YesEFS_WBTFO RM6X16BA	0.14 kg
WBTFORM4X24 BA	Black	101.6 mm	600.2 mm	3048mm	YesEFS_WBTFO RM4X24BA	0.16 kg
WBTFORM6X18 BA	Black	152.4 mm	447.8 mm	3048mm	Yes	0.16 kg
WBTFORM6X20 BA	Black	152.4 mm	498.6 mm	3048mm	YesEFS_WBTFO RM6X20BA	0.18 kg
WBTFORM6X24 BA	Black	152.4 mm	600.2 mm	3048mm	Yes	0.18 kg

DIAGRAMS

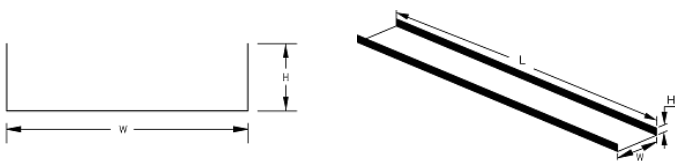

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

