


WBT Performance Cable Tray PreForm Elbow 90°

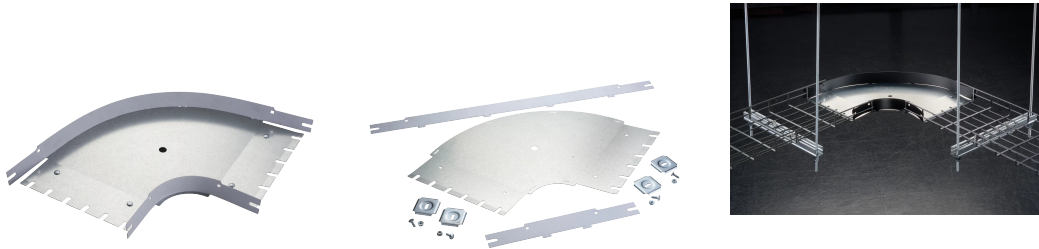

The nVent CADDY WBT Performance Cable Tray PreForm Elbow features a radius junction with a pre-galvanized base and interlocking polymer side walls that save time with consistent installation. The PreForm Elbow 90° is a revolutionary solution for seamless intersections ensuring clean engineering precision and effortless attachment without cutting or configuring. Due to its unique design, this offering provides up to 60% reduction in labor and time compared to traditional methods while maintaining flexibility and cost-effectiveness in tray pathway retrofits.

CERTIFICATIONS



FEATURES

Labor savings up to 60%

Maintains UL classification throughout installation

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2

Catalog Number	Color	Height	Width	Length	Angle	Unit Weight
----------------	-------	--------	-------	--------	-------	-------------

WBTR902X4		50.8 mm	101.6 mm	545.8mm	90 °	0.454 kg
WBTR902X4BA	Black	50.8 mm	101.6 mm	545.8mm	90 °	0.454 kg
WBTR902X4WH	White	50.8 mm	101.6 mm	545.8mm	90 °	0.454 kg
WBTR902X6		50.8 mm	152.4 mm	624.21mm	90 °	0.907 kg
WBTR902X6BA	Black	50.8 mm	152.4 mm	624.21mm	90 °	0.907 kg
WBTR902X6WH	White	50.8 mm	152.4 mm	624.21mm	90 °	0.907 kg
WBTR902X8		50.8 mm	203.2 mm	705.54mm	90 °	0.907 kg
WBTR902X8BA	Black	50.8 mm	203.2 mm	705.54mm	90 °	0.907 kg
WBTR902X8WH	White	50.8 mm	203.2 mm	705.54mm	90 °	0.907 kg
WBTR902X12		50.8 mm	304.8 mm	858.67mm	90 °	1.814 kg
WBTR902X12BA	Black	50.8 mm	304.8 mm	858.67mm	90 °	1.814 kg
WBTR902X12WH	White	50.8 mm	304.8 mm	858.67mm	90 °	1.814 kg
WBTR902X16		50.8 mm	406.4 mm	1020.62mm	90 °	2.722 kg
WBTR902X16WH	White	50.8 mm	406.4 mm	1020.62mm	90 °	2.722 kg
WBTR902X18		50.8 mm	457.2 mm	1099.39mm	90 °	3.175 kg
WBTR902X18BA	Black	50.8 mm	457.2 mm	1099.39mm	90 °	3.175 kg
WBTR902X18WH	White	50.8 mm	457.2 mm	1099.39mm	90 °	3.175 kg

WBTR902X20B A	Black	50.8 mm	508 mm	1178mm	90 °	4.082 kg
WBTR902X24		50.8 mm	609.6 mm	1256.49mm	90 °	4.99 kg
WBTR902X24B A	Black	50.8 mm	609.6 mm	1256.49mm	90 °	4.99 kg
WBTR902X24W H	White	50.8 mm	609.6 mm	1256.49mm	90 °	4.99 kg

Table 2/2

Catalog Number	Certifications
WBTR902X4	cUL, UL
WBTR902X4BA	
WBTR902X4WH	
WBTR902X6	UL, cUL
WBTR902X6BA	
WBTR902X6WH	
WBTR902X8	cUL, UL
WBTR902X8BA	
WBTR902X8WH	
WBTR902X12	cUL, UL
WBTR902X12BA	
WBTR902X12WH	
WBTR902X16	UL, cUL

Catalog Number	Certifications
WBTR902X16WH	
WBTR902X18	cUL, UL
WBTR902X18BA	
WBTR902X18WH	
WBTR902X20BA	
WBTR902X24	UL, cUL
WBTR902X24BA	
WBTR902X24WH	

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

