

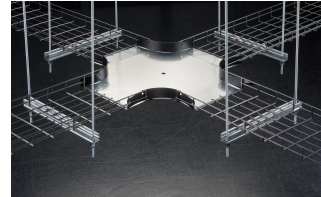


WBT Performance Cable Tray PreForm Intersection

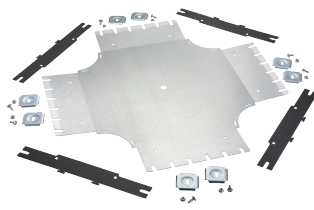

nVent CADDY WBT Performance Cable Tray PreForm is a cleaner, faster and more uniform engineered solution for pathway bends, tees and intersections. The PreForm is a revolutionary, time-saving solution for seamless intersections, ensuring clean engineering, precision with effortless attachment and no cutting or configuring required. This product offers up to 60% reduction in labor and time compared to traditional methods due to the ability to maintain flexibility and cost-effectiveness in any tray pathway retrofit.

CERTIFICATIONS

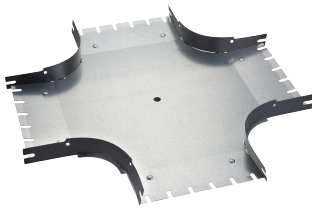

FEATURES

Labor savings up to 60%

Maintains UL classification throughout installation

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/1

Catalog Number	Color	Height	Width	Length	Unit Weight	Certifications
----------------	-------	--------	-------	--------	-------------	----------------

WBTI2X4		50.8 mm	511.48 mm	511.48mm	0.907 kg	cUL, UL
WBTI2X4BA	Black	50.8 mm	511.48 mm	511.48mm	0.907 kg	
WBTI2X4WH	White	50.8 mm	511.48 mm	511.48mm	0.907 kg	
WBTI2X6		50.8 mm	561.34 mm	561.34mm	1.361 kg	UL, cUL
WBTI2X6BA	Black	50.8 mm	561.34 mm	561.34mm	1.361 kg	
WBTI2X8		50.8 mm	612.14 mm	612.14mm	2.268 kg	cUL, UL
WBTI2X8BA	Black	50.8 mm	612.14 mm	612.14mm	2.268 kg	
WBTI2X8WH	White	50.8 mm	612.14 mm	612.14mm	2.268 kg	
WBTI2X12		50.8 mm	711.2 mm	711.2mm	3.175 kg	UL, cUL
WBTI2X12BA	Black	50.8 mm	711.2 mm	711.2mm	3.175 kg	
WBTI2X12WH	White	50.8 mm	711.2 mm	711.2mm	3.175 kg	
WBTI2X16BA	Black	50.8 mm	812.8 mm	812.8mm	4.536 kg	
WBTI2X18		50.8 mm	861.06 mm	861.06mm	5.443 kg	UL, cUL
WBTI2X18BA	Black	50.8 mm	861.06 mm	861.06mm	5.443 kg	
WBTI2X20		50.8 mm	911.86 mm	911.86mm	6.35 kg	cUL, UL
WBTI2X20BA	Black	50.8 mm	911.86 mm	911.86mm	6.35 kg	
WBTI2X24		50.8 mm	1016 mm	1016mm	8.165 kg	UL, cUL
WBTI2X24BA	Black	50.8 mm	1016 mm	1016mm	8.165 kg	
WBTI2X24WH	White	50.8 mm	1016 mm	1016mm	8.165 kg	

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

